 


T-type timing belt **per metre**




Pitch
T5
T10

Steel cored polyurethane



- Pitches: 2.5, 5 and 10mm
- **For linear movement**
- Secured by rigid connection plates
- Working temp. -20°C to +80°C
- Max. speed 40m/s
- Tolerance over length $\pm 0.8\text{mm}/1000\text{mm}$
- Efficiency: up to 98%

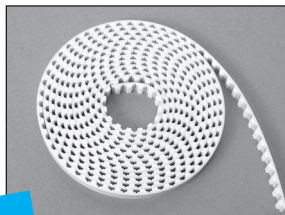

Uses

- Alternating back-and-forth movements


Accessories

- Connecting plate T.../P



For linear positioning

Info.

- Min. length: 1000mm
 - Supplied in multiples of 1 metre
 - When ordering, add the length (L) and the width (l) to the part number (T5M/L/l).
- E.g.: T5M/1000/16

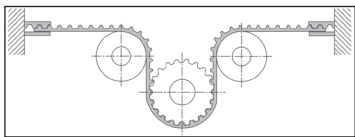

Typical application

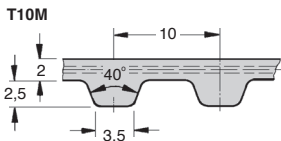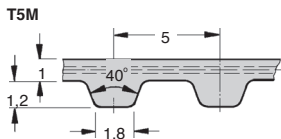

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

		Price 1 to 5, per metre for width					
Part number	Pitch	6mm	10mm	16mm	25mm	32mm	50mm
T5M	T5	19,28 €	25,10 €	29,75 €	56,10 €	-	-
T10M	T10	-	-	35,26 €	47,98 €	61,95 €	68,25 €

Dimensions in mm

Our other products



GE_ES_2RS

Spherical bushing,
Steel / steel with seals



MEFC

Flanged sintered
ferrous bush, Self-
lubricating FP20
ferrous alloy M...



SER69K-CLE

Quarter turn latch for
the food industry,
Stainless steel key



CLB_T

Die cast zinc clamping
lever - male, Zamak



ERT

Sliding nut, For T slot



BAN

Angular clamp,
Adjustable




FIRSTDC1Q60

Speed controller 10A,
10 A



DOMI80

 Domino 80 adjustable
slide, Slide DOMILINE
80



PRT

Rotary table iglidur®,
Iglidur®, aluminium



HK

Manual locking clamp,
Manual locking clamp



ABL100005

Antistatic brush,
Standard



RHTplss

High Temperature
Castor, up to 200kg

Complementary products



T5P_T10P

Connecting plate for T
type timing belts, T10



T10_30_AL

T type timing pulley,
Economy range - T10
aluminium