 


T-type timing belt **per metre**




Pitch
T5
T10

Steel cored polyurethane



- Pitches: 2.5, 5 and 10mm
- **For linear movement**
- Secured by rigid connection plates
- Working temp. -20°C to +80°C
- Max. speed 40m/s
- Tolerance over length $\pm 0.8\text{mm}/1000\text{mm}$
- Efficiency: up to 98%

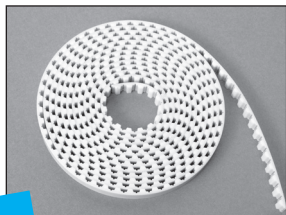

Uses

- Alternating back-and-forth movements


Accessories

- Connecting plate T.../P



For linear positioning

Info.

- Min. length: 1000mm
 - Supplied in multiples of 1 metre
 - When ordering, add the length (L) and the width (l) to the part number (T5M/L/l).
- E.g.: T5M/1000/16

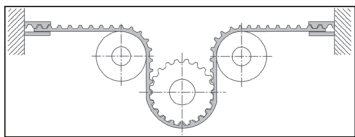

Typical application

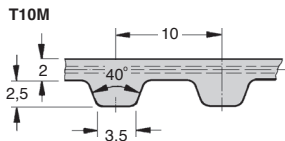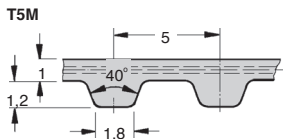

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

		Price 1 to 5, per metre for width					
Part number	Pitch	6mm	10mm	16mm	25mm	32mm	50mm
T5M	T5	19,28 €	25,10 €	29,75 €	56,10 €	-	-
T10M	T10	-	-	35,26 €	47,98 €	61,95 €	68,25 €

Dimensions in mm

Our other products



NPTR
Adjustable cross clamp, Adjustable



BOXdh
Boxed set of cylindrical dowel pins DIN6325, Boxed set - Solid DIN 6...



ETQ
Magnetic label holder for aluminium profile, Label holder



AXTR
Axle for tensioner pulley, Shaft



PM4
Worm and wheel set, Non hardened steel



PSG25S
Spur gear - precision range 303



BSM
Spring plunger with internal hexagonal socket, steel body, plastic pin



ASL
45° Hoist ring for welding, for 45° lifts - for welding




GE_ES
Spherical bushing, Steel / steel



RAG-12-M8
Roller guide accessory, Anchoring system



MET
Cylindrical sintered bronze bush, Self-lubricating sintered

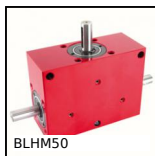


BLHM50
Right angled gearbox, double output shafts, up to 30 Nm

Complementary products



 T5-16ECO
T type timing pulley, Economy range - T5 aluminium



T5courroie
T type timing belt, T5 Steel cored polyurethane