 


T-type timing belt **per metre**



Pitch T5 T10

Steel cored polyurethane



- Pitches: 2.5, 5 and 10mm
- **For linear movement**
- Secured by rigid connection plates
- Working temp. -20°C to +80°C
- Max. speed 40m/s
- Tolerance over length $\pm 0.8\text{mm}/1000\text{mm}$
- Efficiency: up to 98%

Uses

- Alternating back-and-forth movements



Accessories

- Connecting plate T.../P



For linear positioning

Info.

- Min. length: 1000mm
 - Supplied in multiples of 1 metre
 - When ordering, add the length (L) and the width (l) to the part number (T5M/L/l).
- E.g.: T5M/1000/16

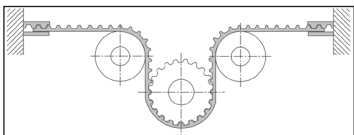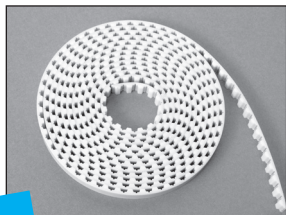

Typical application

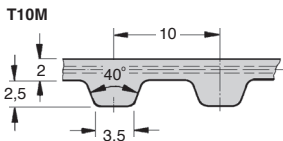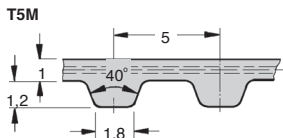

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

		Price 1 to 5, per metre for width					
Part number	Pitch	6mm	10mm	16mm	25mm	32mm	50mm
T5M	T5	19,28 €	25,10 €	29,75 €	56,10 €	-	-
T10M	T10	-	-	35,26 €	47,98 €	61,95 €	68,25 €

Dimensions in mm

Our other products



LBE

Miniature closed linear bearing, Miniature



GP75

Spring loaded toggle latch, Standard (GP75)



BCTH

Mushroom headed button Hygienic Usit®, With female thread and high ...



H1

Crossed helical gear crossed axis at 90°, Steel 20NCD2



DB

Steel bevel gear, 2:1



RTN

BoWex® curved tooth gear coupling, Nylon



SLB

Indexing plunger, steel class 5.8



Q7

Angular contact ball bearing, Steel



PTGT

Tensioner pulley, For V belts



PSPD40

Flexible tube handle, Black PVC



RTE

 
Rotex®, jaw coupling, steel



CHAGC-AL

Screw-in garnet hinge, Screw-on

Complementary products



T5courroie

T type timing belt, T5 Steel cored polyurethane