 


T-type timing belt **per metre**




Pitch
T5
T10

Steel cored polyurethane



- Pitches: 2.5, 5 and 10mm
- **For linear movement**
- Secured by rigid connection plates
- Working temp. -20°C to +80°C
- Max. speed 40m/s
- Tolerance over length $\pm 0.8\text{mm}/1000\text{mm}$
- Efficiency: up to 98%

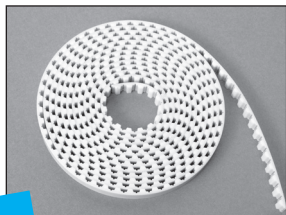

For linear positioning

Uses


- Alternating back-and-forth movements

Accessories



- Connecting plate T.../P

Info.

- Min. length: 1000mm
 - Supplied in multiples of 1 metre
 - When ordering, add the length (L) and the width (l) to the part number (T5M/L/l).
- E.g.: T5M/1000/16

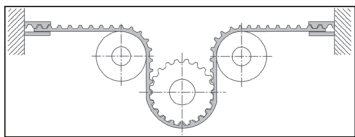

Typical application

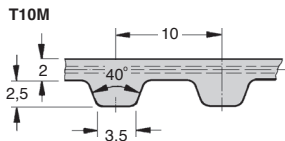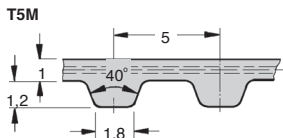

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

		Price 1 to 5, per metre for width					
Part number	Pitch	6mm	10mm	16mm	25mm	32mm	50mm
T5M	T5	19,28 €	25,10 €	29,75 €	56,10 €	-	-
T10M	T10	-	-	35,26 €	47,98 €	61,95 €	68,25 €

Dimensions in mm

Our other products




SH1

Parallel axis helical gear, Steel 20NCD2



GAL22

Conveyor wheel, Zinc plated steel

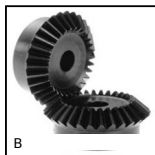

B

Steel bevel gear, 1:1



 
SCR

Suction cup threaded insert, Adaptor for insert




MRAeco

Low cost quick link, Steel



JFM

 Flanged polymer bush, Universal polymer



BH02

Single housed bearing assembly, Bearing secured with circlips



PRF_CLIP_22

Cable clip for aluminium profile, For electric and pneumatic cables



PSPD18

Flexible tube handle, Black PVC



INS

Self tapping steel insert, Steel



PLA

Flat magnet, Flat magnet with threaded hole



GAL48_OMNI

Omni-directional roller, Omni-directional

Complementary products



T5P_T10P

Connecting plate for T type timing belts, T10