 


T-type timing belt **per metre**




Pitch
T5
T10

Steel cored polyurethane



- Pitches: 2.5, 5 and 10mm
- **For linear movement**
- Secured by rigid connection plates
- Working temp. -20°C to +80°C
- Max. speed 40m/s
- Tolerance over length $\pm 0.8\text{mm}/1000\text{mm}$
- Efficiency: up to 98%

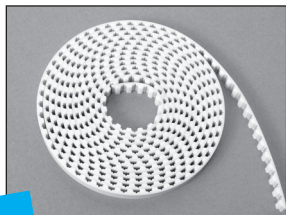

Uses

- Alternating back-and-forth movements


Accessories

- Connecting plate T.../P



For linear positioning

Info.

- Min. length: 1000mm
 - Supplied in multiples of 1 metre
 - When ordering, add the length (L) and the width (l) to the part number (T5M/L/l).
- E.g.: T5M/1000/16

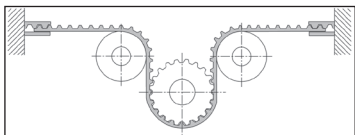

Typical application

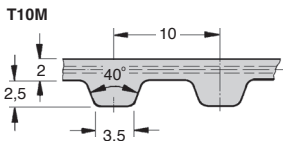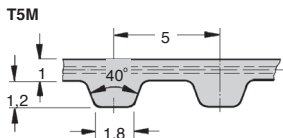

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

		Price 1 to 5, per metre for width					
Part number	Pitch	6mm	10mm	16mm	25mm	32mm	50mm
T5M	T5	19,28 €	25,10 €	29,75 €	56,10 €	-	-
T10M	T10	-	-	35,26 €	47,98 €	61,95 €	68,25 €

Dimensions in mm

Our other products



TK

Topball self-aligning linear bearing, Topball self-aligning



MDB_MTB

Moulded plastic bevel gear (nylon), 2:1



PGMSS

Stainless steel pull handle, Stainless steel



PTBss

Threaded eye hook stainless steel, Stainless steel



EBC

Cap nut Hygienic Design®, Compact



TAC_SS

Stainless steel rigging screw (hook/eye), Stainless steel



EFTC

Fixing support, Stainless steel



SVT5

Screwjack with travelling screw, with translating screw



ACL

Joints for aluminium profile, Variable angle hinge



PM4

Worm and wheel set, Non hardened steel



BAGtr

Lead screw clamping collar, Aluminium



ACL-PL

Joining plate for aluminium profile, Joint plate - 176x86 mm

Complementary products



T5P_T10P

Connecting plate for T type timing belts, T10



T10_30_AL

T type timing pulley, Economy range - T10 aluminium