 


T-type timing belt **per metre**



Pitch
T5
T10

Steel cored polyurethane



- Pitches: 2.5, 5 and 10mm
- **For reciprocating movements**
- Fixing via rigid connection plates
- Working temp. -20°C to +80°C
- Max. speed 40m/s
- Tolerance over length $\pm 0.8\text{mm}/1000\text{mm}$
- Output up to 98%

Uses

- Alternating back-and-forth movements



Accessories

- Connecting plate T.../P



For linear positioning

Info.

- Min. length: 1000mm
 - Supplied in multiples of 1 metre
 - When ordering, add the length (L) and the width (l) to the part number (T5M/L/l).
- E.g.: T5M/1000/16

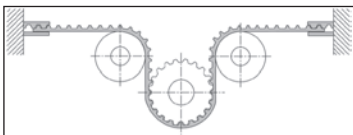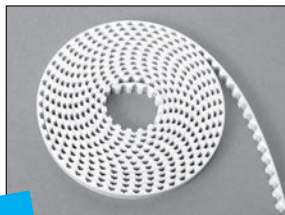

Typical application

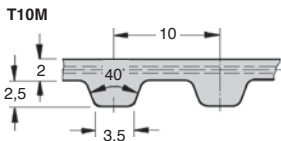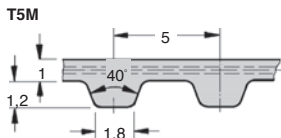

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List	-7%	-14%	-20%	-24%	On request


		Price 1 to 5, per metre for widths					
Part number	Pitch	6mm	10mm	16mm	25mm	32mm	50mm
T5M	T5	17,64 €	22,98 €	27,20 €	51,29 €	-	-
T10M	T10	-	-	32,26 €	43,88 €	56,65 €	62,39 €

Dimensions in mm

Our other products



 BPM-Z
Plastic slotted spring plunger with ball tip, Plastic body + stainless steel tip



PRF_PSA
Shaft support for aluminium profile, Shaft support



DOMI120
Accessories, Turntable



BAC105
Storage bin, 8mm



WJUM20
Drylin® W bearing block, Slide



TCL-ECL
Adjusting nut, Fine thread



STU
Stroke rotary bushing, Steel



G0
Steel spur gear, Steel 20NCD2




PSG35
Spur gear - precision range, Stainless steel 303



PTAF100-PAMF100
Articulated fixable foot with pressed base Ø100, Ø100



 BPHFclip
Clip for ball transfer unit, Insert clip - Installing from above




TPR
High helix leadscrew, Leadscrew only - up to 40mm per rotation

Complementary products



 T5-16ECO
T type timing pulley, Economy range - T5 aluminium



T5courroie
T type timing belt, T5 Steel cored polyurethane