 


# T-type timing belt **per metre**




Pitch  
**T5**  
**T10**

Steel cored polyurethane



- Pitches: 2.5, 5 and 10mm
- **For linear movement**
- Secured by rigid connection plates
- Working temp. -20°C to +80°C
- Max. speed 40m/s
- Tolerance over length  $\pm 0.8\text{mm}/1000\text{mm}$
- Efficiency: up to 98%

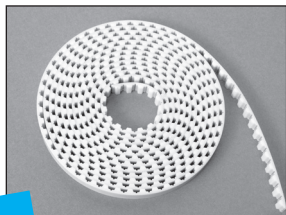

**For linear positioning**

## Uses


- Alternating back-and-forth movements

## Accessories



- Connecting plate T.../P

## Info.

- Min. length: 1000mm
  - Supplied in multiples of 1 metre
  - When ordering, add the length (L) and the width (l) to the part number (T5M/L/l).
- E.g.: T5M/1000/16

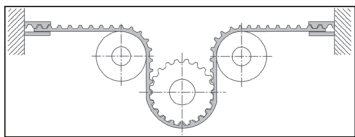

Typical application

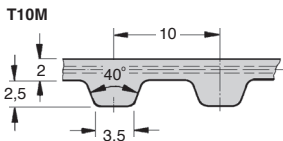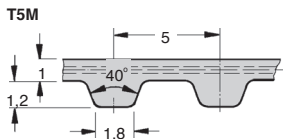

## DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

		Price 1 to 5, per metre for width					
Part number	Pitch	6mm	10mm	16mm	25mm	32mm	50mm
T5M	T5	19,28 €	25,10 €	29,75 €	56,10 €	-	-
T10M	T10	-	-	35,26 €	47,98 €	61,95 €	68,25 €

Dimensions in mm

## Our other products



T5-16ECO

T type timing pulley,  
Economy range - T5  
aluminium



EX

Optional shaft for E-  
type gear reducers, E  
Gearboxes single  
sided ou...



CHAC4040SS

Square hinge with  
riveted pin, drilled,  
Square with riveted  
pin, dri...



PSPD40

Flexible tube handle,  
Black PVC



BLH20

Right angled gearbox,  
from 0.53 to 1.77



VDSQCB

Sliding lock  
adjustment system,  
Blocking wedge




PSG15

Spur gear - precision  
range, Stainless steel  
303



ZG1

 Plastic spur gear,  
Machined plastic  
(delrin)



PRF LIS

Door seal for  
aluminium profile,



PDD

Actuating plunger,  
Non-rotating detector



AT10-BAR

AT type tooth bar  
stock, AT10



EPE

Wing nuts Hygienic  
Design®, Narrow

## Complementary products



T5P\_T10P

Connecting plate for T  
type timing belts, T10