

# Connecting plate for T type timing belts


For T5M and T10M timing belts

Pitch  
**T5**  
**T10**


- For linear movement
- Rigid connecting plate
- Pitch: 5 or 10mm
- For use with **T5M** and **T10M** belts supplied by the metre
- Material:  
Aluminium

## Uses

- For closing a belt or attaching one end of a belt to a frame

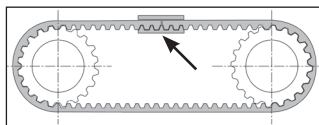

Typical application

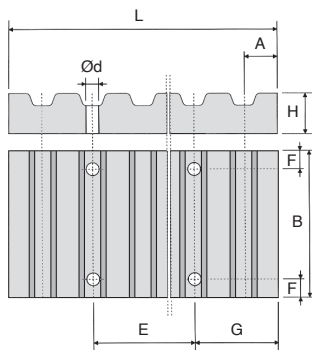

## DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Pitch	B	L	H	E	F	G	Ød	A	Belt width	Stock*	Price each 1 to 5
T5/25P	T5	44	41,5	8	25	6	8,25	5,5	3,25	25	✓	18,46 €
T10/25P	T10	50	80,0	15	50	8	15,00	9,0	5,00	25	✓	26,34 €
T10/32P	T10	57	80,0	15	50	8	15,00	9,0	5,00	32	✓	27,67 €
T10/50P	T10	75	80,0	15	50	8	15,00	9,0	5,00	50	✓	30,22 €

\*Depending on availability - Dimensions in mm

## Our other products



Stainless steel diaboloid shaped elasto mount, Stainless steel



Drylin R® linear bearing housing, Closed - Long



Actuator guide kit, Long bearing



Stainless steel progressive stop, stainless steel



Friction clutch, 30 to 240 Nm



Worm and wheel set, Bronze



Spherical tilt washer - DIN6319, concave



Box set of Nitrile O-rings in nitrile, 3.00 x 2.00mm to 45.20 x 4.00



Adjustment bushing for half-rail guide, Adjustment bushing



Parallel axis helical gear, Steel 20NCD2



Locking bolt support bracket, Mounting holes at 90° to



Pin for magnetic bush, Fast and light magnetic locking

## Complementary products



T type timing belt per metre, T10 Steel cored polyurethane