

Connecting plate for T type timing belts


For T5M and T10M timing belts

Pitch
T5
T10


- For **linear movement**
- Rigid connecting plate
- Pitch: 5 or 10mm
- For use with **T5M** and **T10M** belts supplied by the metre
- Material:
Aluminium

Uses

- For closing a belt or attaching one end of a belt to a frame

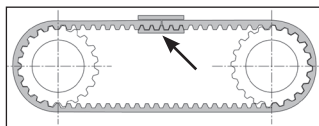

Typical application

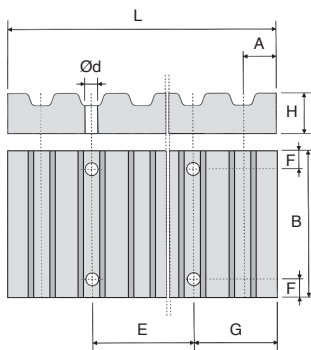

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Pitch	B	L	H	E	F	G	Ød	A	Belt width	Stock*	Price each 1 to 5
T5/25P	T5	44	41,5	8	25	6	8,25	5,5	3,25	25	✓	18,46 €
T10/25P	T10	50	80,0	15	50	8	15,00	9,0	5,00	25	✓	26,34 €
T10/32P	T10	57	80,0	15	50	8	15,00	9,0	5,00	32	✓	27,67 €
T10/50P	T10	75	80,0	15	50	8	15,00	9,0	5,00	50	✓	30,22 €

*Depending on availability - Dimensions in mm

Our other products



GTCSS

Belt tensiometer, For use in hostile environments



CHAK

Hi-Klik™ indent hinge, Hi-Klik™ - Detent hinge



MDPOT

Potentiometer,



ZG0

Plastic spur gear, Machined plastic (delrin)



CAP815

Slim slat top chain stainless steel, Narrow range 815



MCL

Cylindrical threaded sleeve, Cylindrical - stainless steel



PTAF80-PAMF80

Articulated fixable foot with pressed base Ø80, Ø 80



HTD5M_15

HTD Heavy duty timing pulley, HTD5 Steel



MFBS

Stainless steel flexible bellows coupling, Stainless steel - with se...



AC156-157

Strike for toggle latch, 25.5mm



PCS75K

Chain sprocket with hardened teeth, 19.05mm (DIN12B-1)



CHAC4040NP

Square hinge with riveted pin, not drilled, Square with riveted pin,...

Complementary products



T5M_T10M

T type timing belt per metre, T10 Steel cored polyurethane