

Connecting plate for T type timing belts


For T5M and T10M timing belts

Pitch
T5
T10


- For linear movement
- Rigid connecting plate
- Pitch: 5 or 10mm
- For use with **T5M** and **T10M** belts supplied by the metre
- Material:
Aluminium

Uses

- For closing a belt or attaching one end of a belt to a frame

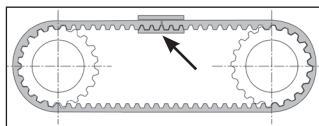

Typical application

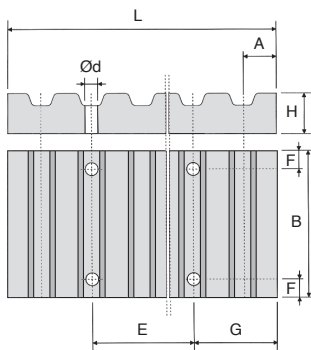

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Pitch	B	L	H	E	F	G	Ød	A	Belt width	Stock*	Price each 1 to 5
T5/25P	T5	44	41,5	8	25	6	8,25	5,5	3,25	25	✓	18,46 €
T10/25P	T10	50	80,0	15	50	8	15,00	9,0	5,00	25	✓	26,34 €
T10/32P	T10	57	80,0	15	50	8	15,00	9,0	5,00	32	✓	27,67 €
T10/50P	T10	75	80,0	15	50	8	15,00	9,0	5,00	50	✓	30,22 €

*Depending on availability - Dimensions in mm

Our other products



MEB

Moulded plastic bevel gear (nylon), 1:1



ABL100005

Antistatic brush, Standard



BEK

Bearing housing for miniature ballscrew, Bearing housing



HG6

Steel spur gear, Steel 20NCD2



VB

Small 6 lobe threaded handle - female, Duroplast - Stainless steel



B_ECO

Eco. range steel bevel gear, 1:1



ACLBDB

Closing mechanism for aluminium profile, Dual ball catch



VLBS

Folding lifting ring for welding, Folding - for welding



NIN

Self-locking nut, Steel



DOMI30

Accessories, Plate



CHTRB

Single and dual output gearboxes, Up to 53,1 Nm



CHA60

Rectangular hinge, drilled or countersunk, Rectangular, drilled or C...

Complementary products



T5M_T10M

T type timing belt per metre, T5 Steel cored polyurethane