

Connecting plate for T type timing belts


For T5M and T10M timing belts

Pitch
T5
T10


- For linear movement
- Rigid connecting plate
- Pitch: 5 or 10mm
- For use with **T5M** and **T10M** belts supplied by the metre
- Material:
Aluminium

Uses

- For closing a belt or attaching one end of a belt to a frame

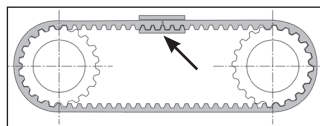

Typical application

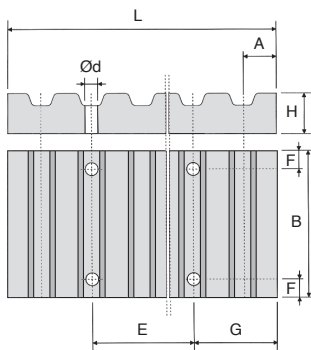

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Pitch	B	L	H	E	F	G	Ød	A	Belt width	Stock*	Price each 1 to 5
T5/25P	T5	44	41,5	8	25	6	8,25	5,5	3,25	25	✓	18,46 €
T10/25P	T10	50	80,0	15	50	8	15,00	9,0	5,00	25	✓	26,34 €
T10/32P	T10	57	80,0	15	50	8	15,00	9,0	5,00	32	✓	27,67 €
T10/50P	T10	75	80,0	15	50	8	15,00	9,0	5,00	50	✓	30,22 €

*Depending on availability - Dimensions in mm

Our other products



GTC

Belt tensiometer, For standard applications



G-ECO

Eco range Spur gear, Steel C45



H0

Crossed helical gear crossed axis at 90°, Steel 20NC22



PP50

Worm and wheel gear reducer, from 6.50 to 12.80 Nm



 
PLM-20SC

Cylindrical magnet, Cylindrical magnet



KKSS

Rounded end feather key, Stainless steel



SLS

Bearing block for leadscrew, Fixed Drylin® bearing block



FBL6000_K19

Brush strip per meter horsehair fibres Ø0.2, Black horsehair



TPEpbd

Castor for aluminium profile, Swivel with



CHAGC-AL

Screw-in garnet hinge, Screw-on



DCG


Suction cup, 2.5 bellows, silicon



PR85

Articulated foot Ø83, Ø 83

 Complementary products



T5M_T10M

T type timing belt per metre, T5 Steel cored polyurethane