

# Connecting plate for T type timing belts


For T5M and T10M timing belts

Pitch  
**T5**  
**T10**


- For linear movement
- Rigid connecting plate
- Pitch: 5 or 10mm
- For use with **T5M** and **T10M** belts supplied by the metre
- Material:  
Aluminium

## Uses

- For closing a belt or attaching one end of a belt to a frame

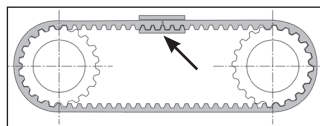

Typical application

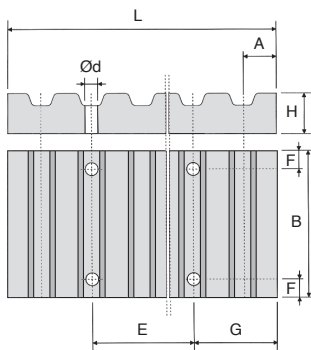

## DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Pitch	B	L	H	E	F	G	Ød	A	Belt width	Stock*	Price each 1 to 5
T5/25P	T5	44	41,5	8	25	6	8,25	5,5	3,25	25	✓	18,46 €
T10/25P	T10	50	80,0	15	50	8	15,00	9,0	5,00	25	✓	26,34 €
T10/32P	T10	57	80,0	15	50	8	15,00	9,0	5,00	32	✓	27,67 €
T10/50P	T10	75	80,0	15	50	8	15,00	9,0	5,00	50	✓	30,22 €

\*Depending on availability - Dimensions in mm

## Our other products



GPLbr

Brush, brass



SH1

Parallel axis helical gear, Machined plastic (delrin)



GG3

Ground spur gear, Heat treated steel



M0

Worm and wheel set, Non hardened steel



RLX

Free running conveyor roller, PVC



T10courroie

T type timing belt, T10 Steel cored polyurethane



CLB\_T

Die cast zinc clamping lever - male, Zamak




DB

Steel bevel gear, 2:1




SC2

 2 part rigid shaft clamp, Clamping jaw



TBV

 Manual lifting tables, 20kg



GMK17\_P

Flat Guide, Flat guide for conical profile



NKIB

Combined bearing with inner ring, Axial load in both directions

## Complementary products



T5M\_T10M

T type timing belt per metre, T10 Steel cored polyurethane