

Connecting plate for T type timing belts


For T5M and T10M timing belts

Pitch
T5
T10


- For linear movement
- Rigid connecting plate
- Pitch: 5 or 10mm
- For use with **T5M** and **T10M** belts supplied by the metre
- Material:
Aluminium

Uses

- For closing a belt or attaching one end of a belt to a frame

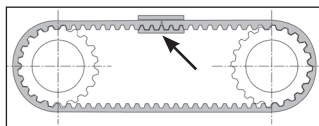

Typical application

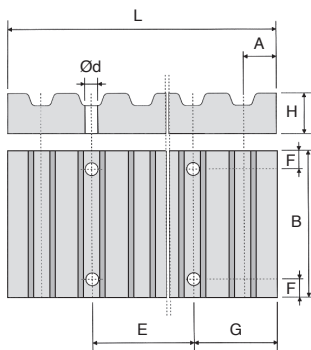

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Pitch	B	L	H	E	F	G	Ød	A	Belt width	Stock*	Price each 1 to 5
T5/25P	T5	44	41,5	8	25	6	8,25	5,5	3,25	25	✓	18,46 €
T10/25P	T10	50	80,0	15	50	8	15,00	9,0	5,00	25	✓	26,34 €
T10/32P	T10	57	80,0	15	50	8	15,00	9,0	5,00	32	✓	27,67 €
T10/50P	T10	75	80,0	15	50	8	15,00	9,0	5,00	50	✓	30,22 €

*Depending on availability - Dimensions in mm

Our other products



PX

Optional output shaft stainless steel, P gearboxes single sided outp...



ACLBS

Closing system for aluminium profile, Spacer for spherical ended stop



ZGO

Plastic spur gear, Machined plastic (delrin)



NCT

Square tube connector, Fixed angle



PAP

Handle for aluminium profile, Ergonomic handle



NKX

Combined bearing without inner ring, Needle and ball bearings



FRtool

Tool for thread repair inserts, Assembly tool



PFL

P-FLEX Coupling, Set screw



FBL6000_K19

Brush strip per meter horsehair fibres Ø0.2, Black horsehair



PDM_PDv

Detectable plastic palm grip, by metal detectors



BPM_LOK

Long-Lok slotted spring plunger with ball tip, LONG-LOK -



HTD14M_55

HTD Heavy duty timing pulley, HTD14 Steel

Complementary products



T5M_T10M

T type timing belt per metre, T10 Steel cored polyurethane