

Connecting plate for T type timing belts

For T5M and T10M timing belts

Pitch
T5
T10


- For linear movements
- Rigid connecting plate
- Pitch: 5 or 10mm
- For use with **T5M** and **T10M** belts supplied by the metre
- Material:
Aluminium

Uses


- For closing a belt or attaching one end of a belt to a frame



Until
-40%^{}**

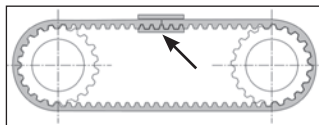

Typical application

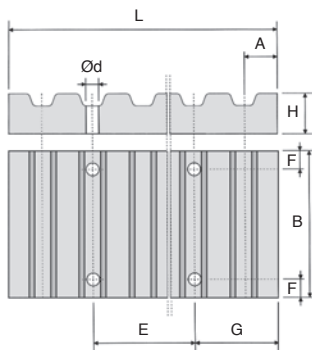

✓ INCREASED STOCK

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Pitch	B	L	H	E	F	G	Ød	A	Belt width	Stock*	Price each 1 to 5
T5/25P	T5	44	41,5	8	25	6	8,25	5,5	3,25	25	✓	16,91 €
T10/25P	T10	50	80,0	15	50	8	15,00	9,0	5,00	25	✓	24,10 €
T10/32P	T10	57	80,0	15	50	8	15,00	9,0	5,00	32	✓	25,31 €
T10/50P	T10	75	80,0	15	50	8	15,00	9,0	5,00	50	✓	27,65 €

Depending of availability - Dimensions in mm

Our other products



RHTtcss
High Temperature
Castor, up to 200kg



RPCpl
Swivel castor with
double brake, Steel -
Polyamide



MEB
Moulded plastic bevel
gear (nylon), 1:1



PO
Pull handle - Multi-
sector, Smooth hole



LVT
Miniature motorised
actuator 1A, 1 ampere



 
PRF_T
Corner reinforcement,
Corner reinforcement



CHAGC-AL
Screw-in garnet
hinge, Screw-on



RAGFLOWsupport
Floway2® Roller track
accessory, Roller
track support



PF20
Worm and wheel gear
reducer, up to 5 Nm



SER69K-CLE
Quarter turn latch for
the food industry,
Stainless steel key




INO
Internal gear, Steel
20NCD2



NT122
Spur gear coaxial
gearbox, from 32 to
85 Nm - In-line

 Complementary products



T5M_T10M
T type timing belt per
metre, T5 Steel cored
polyurethane