

T-type timing belts


 
Stock

Pitch

Steel cored polyurethane

T5

- Pitch 5mm
- Working temp. -30°C to +80°C
- Max. speed 40m/s
- Efficiency: up to 98%

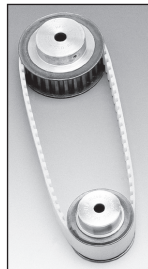

Options

- Belt by the metre **T5M**
- Alternative lengths/widths

Accessories


- **BTE** arm and **GTC** roller belt tensioner

Info.

- When ordering, add the width to the part number

Eg: **T5/120/4**

Compatible with
T5 pulley

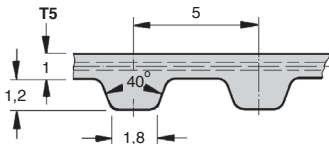

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	Teeth	Stock*	Stock*	Stock*	Price each 1 to 5 for width			
			6mm	10mm	16mm	6mm	10mm	16mm	25mm
T 5/150	150	30	✓	-	-	10,90 €	14,14 €	20,53 €	On request
T 5/185	185	37	✓	✓	✓	11,09 €	14,59 €	21,02 €	
T 5/200	200	40	✓	✓	✓	11,12 €	14,62 €	21,14 €	
T 5/210	210	42	-	✓	-	11,55 €	15,23 €	21,93 €	
T 5/215	215	43	-	-	-	11,22 €	14,84 €	21,35 €	
T 5/220	220	44	-	-	-	11,22 €	14,84 €	21,35 €	
T 5/225	225	45	✓	✓	✓	11,25 €	14,92 €	21,49 €	
T 5/245	245	49	✓	✓	-	11,36 €	15,14 €	21,76 €	
T 5/250	250	50	-	✓	-	11,77 €	15,61 €	22,41 €	
T 5/255	255	51	-	✓	-	11,41 €	14,41 €	21,86 €	
T 5/260	260	52	✓	-	-	11,41 €	15,14 €	21,86 €	
T 5/270	270	54	✓	✓	✓	11,46 €	15,24 €	21,95 €	
T 5/280	280	56	✓	✓	-	11,51 €	15,34 €	22,11 €	
T 5/295	295	59	-	✓	✓	11,61 €	15,54 €	22,33 €	

*Depending on availability - Dimensions in mm

Pitch T5

DISCOUNTS


Qty	1+	6+	20+
Disc. List	-7%	On request	

Part number	Length	Teeth	Stock*	Stock*	Stock*	Price each 1 to 5 for width				
			6mm	10mm	16mm	6mm	10mm	16mm	25mm	
T 5/305	305	61	✓	✓	✓	11,71 €	15,64 €	22,51 €		
T 5/330	330	66	-	✓	✓	11,80 €	15,85 €	22,85 €		
T 5/340	340	68	✓	✓	-	11,80 €	15,92 €	22,95 €		
T 5/355	355	71	✓	✓	✓	11,93 €	16,17 €	23,25 €		
T 5/365	365	73	✓	✓	✓	11,97 €	16,19 €	23,42 €		
T 5/390	390	78	✓	✓	-	11,99 €	16,43 €	23,66 €		
T 5/400	400	80	✓	✓	-	12,10 €	16,51 €	23,76 €		
T 5/410	410	82	-	✓	✓	12,14 €	16,56 €	24,01 €		
T 5/420	420	84	✓	✓	✓	12,21 €	16,64 €	24,10 €		
T 5/455	455	91	✓	✓	✓	12,35 €	16,99 €	24,97 €		
T 5/460	460	92	-	-	-	12,78 €	17,57 €	25,76 €		
T 5/480	480	96	✓	✓	✓	12,43 €	17,36 €	25,47 €		
T 5/500	500	100	✓	✓	✓	12,56 €	17,55 €	25,95 €		
T 5/510	510	102	✓	-	-	12,58 €	17,70 €	26,20 €		
T 5/525	525	105	-	✓	✓	12,80 €	17,97 €	26,70 €		
T 5/545	545	109	-	✓	✓	13,06 €	18,18 €	27,20 €		
T 5/550	550	110	✓	✓	✓	13,06 €	18,18 €	27,20 €		
T 5/560	560	112	✓	✓	✓	13,13 €	18,34 €	27,42 €		
T 5/575	575	115	✓	✓	✓	13,35 €	18,67 €	27,94 €		
T 5/590	590	118	-	✓	-	13,80 €	19,44 €	29,33 €		
T 5/610	610	122	✓	✓	✓	13,69 €	19,11 €	28,89 €		
T 5/620	620	124	✓	-	-	13,78 €	19,25 €	29,18 €		
T 5/630	630	126	✓	✓	-	13,92 €	19,31 €	29,73 €		
T 5/650	650	130	-	-	✓	14,69 €	20,33 €	31,07 €		
T 5/690	690	138	-	✓	✓	14,77 €	20,47 €	31,38 €		
T 5/720	720	144	✓	-	✓	15,14 €	21,02 €	32,37 €		
T 5/750	750	150	-	✓	✓	15,54 €	21,58 €	33,34 €		
T 5/765	765	153	-	-	-	16,44 €	22,68 €	34,92 €		
T 5/780	780	156	-	-	✓	16,04 €	22,18 €	34,14 €		
T 5/815	815	163	-	✓	-	16,56 €	23,13 €	35,27 €		
T 5/840	840	168	-	-	-	16,81 €	23,57 €	36,00 €		
T 5/900	900	180	-	✓	-	17,70 €	24,97 €	37,76 €		
T 5/990	990	198	-	-	-	18,93 €	26,86 €	40,56 €		
T 5/1075	1075	215	-	-	-	20,19 €	27,96 €	43,81 €		
T 5/1100	1100	220	-	-	-	20,47 €	29,12 €	44,22 €		
T 5/1160	1160	232	-	-	-	22,27 €	31,30 €	47,56 €		
T 5/1215	1215	243	-	✓	✓	22,70 €	31,48 €	48,27 €		
T 5/1315	1315	263	-	-	-	25,80 €	34,92 €	52,80 €		
T 5/1380	1380	276	-	-	✓	26,33 €	35,23 €	53,15 €		

On request

*Depending on availability - Dimensions in mm

 Our other products



LSM

Stainless steel 316L leadscrew, Stainless steel - 1 thread



BOX-TOR-MAX

Box set of Nitrile O-rings in nitrile, 2.90 x 1.78mm to 82.14 x 3.53



GMK17_BR

Clamp for guiding profile, Rounded only - single



UFFX

Spare tyre UNEFLEX® coupling, range



CHAsb89

Hinge without pin, Plastic hinge



GBS

Nut for ballscrew, Flanged ballscrew nut



LR

Precision locknut, Precision locknut



GE

Toggle latches, Standard



 
PRF-P

Aluminium profile feet support, For feet or casters



BTC_M

End cap with threaded insert for square tube, With threaded insert



FRss

Stainless steel thread inserts, Stainless steel



FF15

Offset spur gear reducer, from 2.20 to 10 Nm

Complementary products



GTC

Belt tensioner, For standard applications



T5-10ECO

T type timing pulley, Economy range - T5 aluminium



T5-BAR

T type tooth bar stock, T5



T5M_T10M

T type timing belt per metre, T5 Steel cored polyurethane