

- Pitch 2.5mm
- Working temp. -30°C to +80°C
- Max. speed 40m/s
- Efficiency: up to 98%

### Options


- Belt by the metre **T2.5M**
- Alternative lengths/widths

### Info

- When ordering, add the width to the part number  
Eg: T2.5/120/4

### Accessories

- Tensioner TMR/TFR (tome 4 p144)
- Roller belt tensioner GTC (tome 4 p.146)

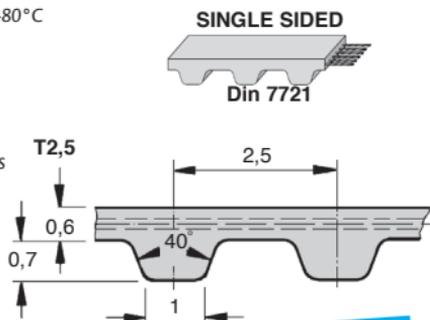

**Compatible with T2.5 pulley**

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	No. of teeth	Stock*	Stock*	Price each 1 to 5 for width		
			4mm	6mm	4mm	6mm	10mm
T 2.5/120	120,00	48	✓	✓	13,26 €	14,72 €	<b>On request</b>
T 2.5/145	145,00	58	✓	✓	13,40 €	14,87 €	
T 2.5/160	160,00	64	✓	✓	13,47 €	14,93 €	
T 2.5/177	177,50	71	✓	✓	13,77 €	15,28 €	
T 2.5/180	180,00	72	✓	-	13,77 €	15,28 €	
T 2.5/182	182,50	73	✓	✓	13,77 €	15,28 €	
T 2.5/200	200,00	80	✓	✓	13,77 €	15,28 €	
T 2.5/230	230,00	92	✓	✓	14,74 €	16,41 €	
T 2.5/245	245,00	98	✓	✓	14,59 €	16,25 €	
T 2.5/265	265,00	106	✓	✓	14,75 €	16,43 €	
T 2.5/285	285,00	114	✓	✓	14,84 €	16,48 €	
T 2.5/290	290,00	116	-	✓	15,43 €	17,19 €	
T 2.5/317	317,50	127	✓	✓	15,38 €	17,11 €	
T 2.5/330	330,00	132	✓	✓	15,56 €	17,28 €	
T 2.5/380	380,00	152	-	✓	16,43 €	18,25 €	
T 2.5/420	420,00	168	-	✓	18,24 €	18,22 €	
T 2.5/480	480,00	192	✓	✓	17,02 €	18,90 €	
T 2.5/500	500,00	200	✓	✓	17,28 €	19,20 €	
T 2.5/600	600,00	240	-	✓	23,68 €	26,31 €	
T 2.5/620	620,00	248	-	✓	24,58 €	27,36 €	
T 2.5/650	650,00	260	-	✓	24,06 €	26,69 €	
T 2.5/780	780,00	312	✓	✓	27,74 €	30,88 €	
T 2.5/950	950,00	380	✓	✓	30,65 €	34,12 €	

\*Depending on availability - Dimensions in mm

# T-type timing belts



## Pitch T5

Steel cored polyurethane

- Pitch 5mm
- Working temp. -30°C to +80°C
- Max. speed 40m/s
- Efficiency: up to 98%



### Options

- Belt by the metre **T5M**
- Alternative lengths/widths


### Info.

- When ordering, add the width to the part number  
Eg: **T5/120/4**

Compatible with  
T5 pulley

### Accessories

- TMR/TFR tensioner  
(tome 4 p.144)
- GTC roller belt tensioner  
(tome 4 p.146)

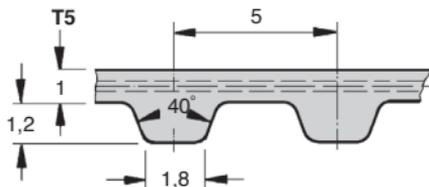

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	Teeth	Stock*	Stock*	Stock*	Price each 1 to 5 for width			
			6mm	10mm	16mm	6mm	10mm	16mm	25mm
T 5/150	150	30	✓	-	-	15,90 €	20,68 €	30,03 €	On request
T 5/185	185	37	✓	✓	✓	16,22 €	21,33 €	30,75 €	
T 5/200	200	40	✓	✓	✓	16,25 €	21,36 €	30,93 €	
T 5/210	210	42	-	✓	-	16,87 €	22,27 €	32,07 €	
T 5/215	215	43	-	-	-	16,39 €	21,69 €	31,21 €	
T 5/220	220	44	-	-	-	16,39 €	21,69 €	31,21 €	
T 5/225	225	45	✓	✓	-	16,43 €	21,82 €	31,46 €	
T 5/245	245	49	✓	✓	-	16,61 €	22,15 €	31,83 €	
T 5/250	250	50	-	✓	-	17,19 €	22,81 €	32,82 €	
T 5/255	255	51	-	✓	-	16,70 €	16,70 €	31,97 €	
T 5/260	260	52	-	-	-	16,70 €	22,15 €	31,97 €	
T 5/270	270	54	✓	✓	✓	16,76 €	22,28 €	32,11 €	
T 5/280	280	56	✓	✓	-	16,82 €	22,45 €	32,36 €	
T 5/295	295	59	-	✓	✓	16,95 €	22,72 €	32,65 €	

\*Depending on availability - Dimensions in mm

# Pitch T5

## DISCOUNTS

Qty	1+	6+	20+
Disc. List	-7%	On request	

Part number	Length	Teeth	Stock*	Stock*	Stock*	Price each 1 to 5 for width			
			6mm	10mm	16mm	6mm	10mm	16mm	25mm
T 5/305	305	61	✓	✓	✓	17,11 €	22,84 €	32,94 €	
T 5/330	330	66	-	✓	-	17,23 €	23,19 €	33,44 €	
T 5/340	340	68	✓	-	-	17,23 €	23,29 €	33,56 €	
T 5/355	355	71	✓	✓	✓	17,41 €	23,63 €	34,01 €	
T 5/365	365	73	-	✓	✓	17,48 €	23,68 €	34,28 €	
T 5/390	390	78	✓	✓	✓	17,53 €	24,02 €	34,63 €	
T 5/400	400	80	-	✓	-	17,70 €	24,14 €	34,77 €	
T 5/410	410	82	-	✓	-	17,74 €	24,20 €	35,14 €	
T 5/420	420	84	✓	✓	✓	17,84 €	24,32 €	35,27 €	
T 5/455	455	91	✓	✓	✓	18,07 €	24,85 €	36,53 €	
T 5/460	460	92	-	-	-	18,68 €	25,69 €	37,68 €	
T 5/480	480	96	-	✓	-	18,17 €	25,38 €	37,28 €	
T 5/500	500	100	-	✓	✓	18,33 €	25,67 €	37,96 €	
T 5/510	510	102	✓	-	-	18,35 €	25,90 €	38,32 €	
T 5/525	525	105	-	✓	-	18,70 €	26,29 €	39,08 €	
T 5/545	545	109	-	-	✓	19,10 €	26,59 €	39,82 €	
T 5/550	550	110	-	-	-	19,10 €	26,59 €	39,82 €	
T 5/560	560	112	-	✓	-	19,20 €	26,82 €	40,13 €	
T 5/575	575	115	-	✓	✓	19,52 €	27,31 €	40,89 €	
T 5/590	590	118	-	-	-	20,14 €	28,43 €	42,93 €	
T 5/610	610	122	-	✓	✓	20,01 €	27,97 €	42,29 €	
T 5/620	620	124	-	-	-	20,12 €	28,15 €	42,71 €	
T 5/630	630	126	-	✓	-	20,34 €	28,23 €	43,52 €	
T 5/650	650	130	-	-	✓	21,48 €	29,73 €	45,50 €	
T 5/690	690	138	-	✓	✓	21,59 €	29,94 €	45,92 €	
T 5/720	720	144	-	-	✓	22,15 €	30,75 €	47,39 €	
T 5/750	750	150	-	✓	-	22,72 €	31,58 €	48,82 €	
T 5/765	765	153	-	-	-	24,04 €	33,19 €	51,10 €	
T 5/780	780	156	-	-	✓	23,46 €	32,44 €	49,99 €	
T 5/815	815	163	-	-	-	24,20 €	33,82 €	51,61 €	
T 5/840	840	168	-	-	-	24,58 €	34,48 €	52,71 €	
T 5/900	900	180	-	✓	-	25,90 €	36,53 €	55,30 €	
T 5/990	990	198	-	-	-	27,69 €	39,29 €	59,38 €	
T 5/1075	1075	215	-	-	-	29,53 €	40,91 €	64,14 €	
T 5/1100	1100	220	-	-	-	29,94 €	42,61 €	64,74 €	
T 5/1160	1160	232	-	-	-	32,55 €	45,81 €	69,64 €	
T 5/1215	1215	243	-	✓	✓	33,23 €	46,08 €	70,67 €	
T 5/1315	1315	263	-	-	-	37,77 €	51,10 €	77,32 €	
T 5/1380	1380	276	-	-	-	38,52 €	51,56 €	77,83 €	

On request

\*Depending on availability - Dimensions in mm

# T-type belt



## Pitch T10

Polyurethane with steel core

- Pitch 10mm
- Working temp. -30°C to +80°C
- Max. speed 40m/s
- Efficiency: up to 98%

### Options

- Belt by the metre **T10M**
- Alternative lengths/widths

### Info.

- When ordering, add the width to the part number.

Eg: T10/120/4

### Accessories

- TMR/TFR tensioner (tome 4 p144)
- GTC roller belt tensioner (tome 4 p.146)



Compatible with T10 pulley


### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	No. of teeth	Price each 1 to 5 for width			
			16mm	25mm	32mm	50mm
T 10/260	260	26	37,09 €	51,46 €	On request	On request
T 10/370	370	37	40,12 €	56,02 €		
T 10/410	410	41	41,56 €	57,79 €		
T 10/500	500	50	44,93 €	61,45 €		
T 10/530	530	53	45,96 €	63,02 €		
T 10/560	560	56	47,78 €	65,16 €		
T 10/600	600	60	49,14 €	66,70 €		
T 10/610	610	61	49,34 €	67,44 €		
T 10/630	630	63	50,81 €	68,85 €		
T 10/660	660	66	52,26 €	71,08 €		
T 10/680	680	68	46,72 €	78,63 €		
T 10/690	690	69	53,77 €	73,35 €		
T 10/700	700	70	55,88 €	66,50 €		
T 10/720	720	72	55,56 €	75,90 €		
T 10/730	730	73	53,25 €	83,09 €		
T 10/750	750	75	58,67 €	85,01 €		

Dimensions in mm

# Pitch T10

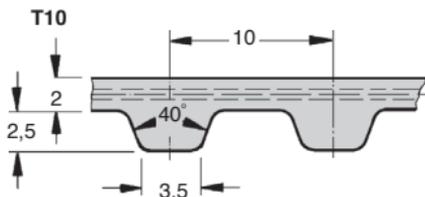

## DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	No. of teeth	Price each 1 to 5 for width			
			16mm	25mm	32mm	50mm
T 10/780	780	78	58,94 €	80,69 €	On request	On request
T 10/810	810	81	60,76 €	83,25 €		
T 10/840	840	84	62,65 €	85,94 €		
T 10/880	880	88	64,77 €	89,58 €		
T 10/890	890	89	65,53 €	91,06 €		
T 10/920	920	92	67,44 €	94,00 €		
T 10/960	960	96	69,61 €	98,39 €		
T 10/970	970	97	70,36 €	99,60 €		
T 10/980	980	98	71,08 €	100,62 €		
T 10/1010	1010	101	73,35 €	103,61 €		
T 10/1080	1080	108	77,40 €	110,24 €		
T 10/1110	1110	111	79,83 €	122,82 €		
T 10/1140	1140	114	81,45 €	116,22 €		
T 10/1150	1150	115	81,80 €	116,85 €		
T 10/1210	1210	121	85,94 €	123,16 €		
T 10/1240	1240	124	88,16 €	125,68 €		
T 10/1250	1250	125	88,43 €	126,87 €		
T 10/1300	1300	130	92,09 €	131,71 €		
T 10/1320	1320	132	93,26 €	133,51 €		
T 10/1350	1350	135	95,14 €	136,46 €		
T 10/1390	1390	139	98,05 €	140,58 €		
T 10/1400	1400	140	98,82 €	141,24 €		
T 10/1420	1420	142	99,94 €	143,07 €		
T 10/1460	1460	146	102,54 €	146,85 €		
T 10/1500	1500	150	-	163,14 €		
T 10/1560	1560	156	106,97 €	155,66 €		
T 10/1610	1610	161	112,50 €	161,22 €		
T 10/1750	1750	175	122,45 €	176,71 €		
T 10/1780	1780	178	124,62 €	179,98 €		
T 10/1880	1880	188	132,05 €	191,11 €		
T 10/1960	1960	196	140,18 €	202,18 €		
T 10/2250	2250	225	173,01 €	254,04 €		

Dimensions in mm

# T-type timing belt **per metre**




Pitch  
**T5**  
**T10**

Steel cored polyurethane



- Pitches: 2.5, 5 and 10mm
- **For linear movement**
- Secured by rigid connection plates
- Working temp. -20°C to +80°C
- Max. speed 40m/s
- Tolerance over length  $\pm 0.8\text{mm}/1000\text{mm}$
- Efficiency: up to 98%

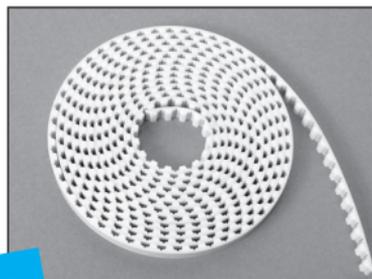

**For linear positioning**

## Uses


- Alternating back-and-forth movements

## Info.


- Min. length: 1000mm
- Supplied in multiples of 1 metre
- When ordering, add the length (L) and the width (l) to the part number (T5M/L/l).
- E.g.: **T5M/1000/16**

## Accessories

- T.../P connecting plate (**tome 4 p.59**)
- T pulley (**tome 4 p.45**)

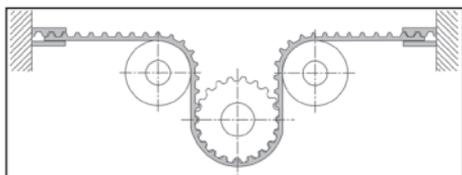

Typical application

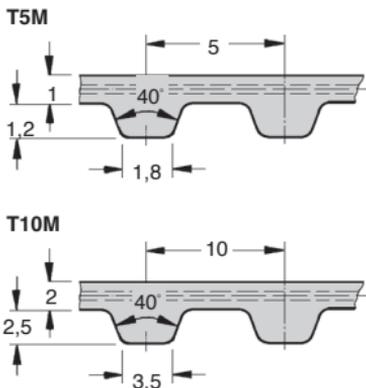

## DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

		Price 1 to 5, per metre for width					
Part number	Pitch	6mm	10mm	16mm	25mm	32mm	50mm
T5M	T5	23,97 €	31,21 €	36,99 €	69,76 €	-	-
T10M	T10	-	-	43,85 €	59,66 €	77,04 €	84,87 €

Dimensions in mm

# Connecting plate for T type timing belts

For T5M and T10M timing belts

Pitch  
**T5**  
**T10**


- For linear movement
- Rigid connecting plate
- Pitch: 5 or 10mm
- For use with **T5M** and **T10M** belts supplied by the metre
- Material:  
Aluminium

## Uses


- For closing a belt or attaching one end of a belt to a frame

## Accessories

- T.M connecting plate (tome 4 p.5859)
- T pulley (tome 4 p.45)

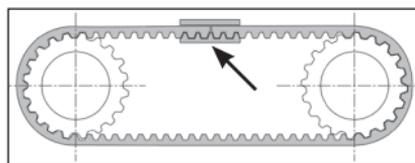

Typical application

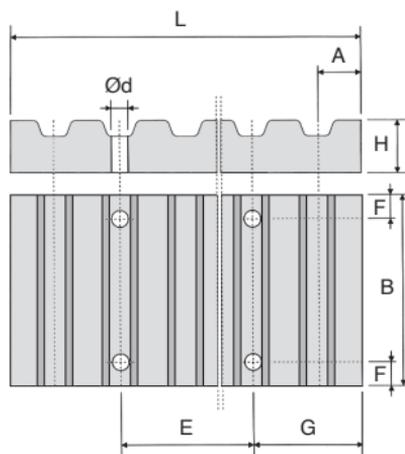

## DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Pitch	B	L	H	E	F	G	Ød	A	Belt width	Stock*	Price each 1 to 5
T5/25P	T5	44	41,5	8	25	6	8,25	5,5	3,25	25	✓	16,87 €
T10/25P	T10	50	80,0	15	50	8	15,00	9,0	5,00	25	✓	23,00 €
T10/32P	T10	57	80,0	15	50	8	15,00	9,0	5,00	32	✓	24,12 €
T10/50P	T10	75	80,0	15	50	8	15,00	9,0	5,00	50	✓	26,40 €

\*Depending on availability - Dimensions in mm