

 
# T-type timing belts



## Pitch T5

Steel cored polyurethane

- Pitch 5mm
- Working temp. -30°C to +80°C
- Max. speed 40m/s
- Efficiency: up to 98%



### Options

- Belt by the metre **T5M**
- Alternative lengths/widths

### Accessories


- **BTE** arm and **GTC** roller belt tensioner

### Info.

- When ordering, add the width to the part number

Eg: **T5/120/4**

Compatible with  
T5 pulley

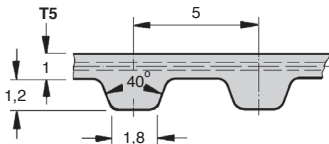

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	Teeth	Stock*			Price each 1 to 5 for width				On request
			6mm	10mm	16mm	6mm	10mm	16mm	25mm	
T 5/150	150	30	✓	-	-	10,90 €	14,14 €	20,53 €		On request
T 5/185	185	37	✓	✓	✓	11,09 €	14,59 €	21,02 €		
T 5/200	200	40	✓	✓	✓	11,12 €	14,62 €	21,14 €		
T 5/210	210	42	-	✓	-	11,55 €	15,23 €	21,93 €		
T 5/215	215	43	-	-	-	11,22 €	14,84 €	21,35 €		
T 5/220	220	44	-	-	-	11,22 €	14,84 €	21,35 €		
T 5/225	225	45	✓	✓	✓	11,25 €	14,92 €	21,49 €		
T 5/245	245	49	✓	✓	-	11,36 €	15,14 €	21,76 €		
T 5/250	250	50	-	✓	-	11,77 €	15,61 €	22,41 €		
T 5/255	255	51	-	✓	-	11,41 €	14,41 €	21,86 €		
T 5/260	260	52	✓	-	-	11,41 €	15,14 €	21,86 €		
T 5/270	270	54	✓	✓	✓	11,46 €	15,24 €	21,95 €		
T 5/280	280	56	✓	✓	-	11,51 €	15,34 €	22,11 €		
T 5/295	295	59	-	✓	✓	11,61 €	15,54 €	22,33 €		

\*Depending on availability - Dimensions in mm

# Pitch T5

## DISCOUNTS

Qty	1+	6+	20+
Disc. List	-7%	On request	

Part number	Length	Teeth	Stock*	Stock*	Stock*	Price each 1 to 5 for width				
			6mm	10mm	16mm	6mm	10mm	16mm	25mm	
T 5/305	305	61	✓	✓	✓	11,71 €	15,64 €	22,51 €		
T 5/330	330	66	-	✓	✓	11,80 €	15,85 €	22,85 €		
T 5/340	340	68	✓	✓	-	11,80 €	15,92 €	22,95 €		
T 5/355	355	71	✓	✓	✓	11,93 €	16,17 €	23,25 €		
T 5/365	365	73	✓	✓	✓	11,97 €	16,19 €	23,42 €		
T 5/390	390	78	✓	✓	-	11,99 €	16,43 €	23,66 €		
T 5/400	400	80	✓	✓	-	12,10 €	16,51 €	23,76 €		
T 5/410	410	82	-	✓	✓	12,14 €	16,56 €	24,01 €		
T 5/420	420	84	✓	✓	✓	12,21 €	16,64 €	24,10 €		
T 5/455	455	91	✓	✓	✓	12,35 €	16,99 €	24,97 €		
T 5/460	460	92	-	-	-	12,78 €	17,57 €	25,76 €		
T 5/480	480	96	✓	✓	✓	12,43 €	17,36 €	25,47 €		
T 5/500	500	100	✓	✓	✓	12,56 €	17,55 €	25,95 €		
T 5/510	510	102	✓	-	-	12,58 €	17,70 €	26,20 €		
T 5/525	525	105	-	✓	✓	12,80 €	17,97 €	26,70 €		
T 5/545	545	109	-	✓	✓	13,06 €	18,18 €	27,20 €		
T 5/550	550	110	✓	✓	✓	13,06 €	18,18 €	27,20 €		
T 5/560	560	112	✓	✓	✓	13,13 €	18,34 €	27,42 €		
T 5/575	575	115	✓	✓	✓	13,35 €	18,67 €	27,94 €		
T 5/590	590	118	-	✓	-	13,80 €	19,44 €	29,33 €		
T 5/610	610	122	✓	✓	✓	13,69 €	19,11 €	28,89 €		
T 5/620	620	124	✓	-	-	13,78 €	19,25 €	29,18 €		
T 5/630	630	126	✓	✓	-	13,92 €	19,31 €	29,73 €		
T 5/650	650	130	-	-	✓	14,69 €	20,33 €	31,07 €		
T 5/690	690	138	-	✓	✓	14,77 €	20,47 €	31,38 €		
T 5/720	720	144	✓	-	✓	15,14 €	21,02 €	32,37 €		
T 5/750	750	150	-	✓	✓	15,54 €	21,58 €	33,34 €		
T 5/765	765	153	-	-	-	16,44 €	22,68 €	34,92 €		
T 5/780	780	156	-	-	✓	16,04 €	22,18 €	34,14 €		
T 5/815	815	163	-	✓	-	16,56 €	23,13 €	35,27 €		
T 5/840	840	168	-	-	-	16,81 €	23,57 €	36,00 €		
T 5/900	900	180	-	✓	-	17,70 €	24,97 €	37,76 €		
T 5/990	990	198	-	-	-	18,93 €	26,86 €	40,56 €		
T 5/1075	1075	215	-	-	-	20,19 €	27,96 €	43,81 €		
T 5/1100	1100	220	-	-	-	20,47 €	29,12 €	44,22 €		
T 5/1160	1160	232	-	-	-	22,27 €	31,30 €	47,56 €		
T 5/1215	1215	243	-	✓	✓	22,70 €	31,48 €	48,27 €		
T 5/1315	1315	263	-	-	-	25,80 €	34,92 €	52,80 €		
T 5/1380	1380	276	-	-	✓	26,33 €	35,23 €	53,15 €		

On request

\*Depending on availability - Dimensions in mm

## Our other products




PPD

Indexing plunger for sheets, For sheet metal



TRMSS

Spur round rack, Stainless steel - module 1-5

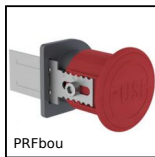

PRFbou

Emergency release button for aluminium profile, Emergency release bu...



DOMI120

Accessories, Clamping lever



 
RFVcap

Stainless steel protective cover, Open protective cover



AT5P\_AT10P

Connecting plate for AT type timing belts, AT10



RPP8

RPP heavy duty timing belt, RPP8




LRR22

Small dimension latch with locking system, Aluminium



EML

 Stainless steel hexagonal headed thumb nut, Lobed handscrew



H0

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



PSG125

Spur gear - precision range, Pre-hardened Steel 35NCD6



METC

Flanged sintered bronze bush, Self-lubricating sintered bronze

## Complementary products



GTC

Belt tensioner, For standard applications



T5-BAR

T type tooth bar stock, T5



T5-10ECO

T type timing pulley, Economy range - T5 aluminium



T5M\_T10M

T type timing belt per metre, T5 Steel cored polyurethane