

Stainless steel rigging screw with hook/eye



Turnbuckle

TACss

- Rigging screw with eye and hook
- Fitting component
- Material: stainless steel 316

Info.

- SWL: safe working load.
- The Safe Working Load is calculated by dividing the breaking load by a factor of safety of 3

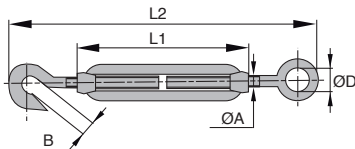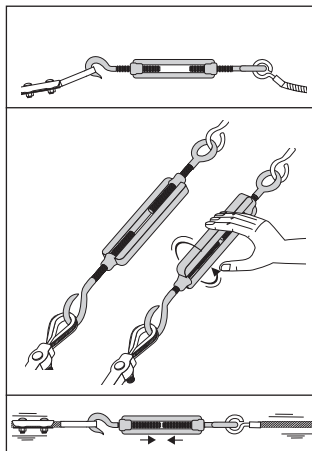

DISCOUNTS

Qty	1+	5+	10+	20+	30+
Disc. List	-5%	-10%	-15%	On request	

Part number	ØA	B	ØD	L1	L2	SWL (kg)	Weight (kg)	Stock*	Price each 1 to 4
TAC1-05/SS	M5	9	8,3	71	122-179	180	0,046	✓	9,38 €
TAC1-06/SS	M6	9,5	10,0	90	160-228	360	0,076	✓	11,24 €
TAC1-08/SS	M8	11	12,0	120	210-303	650	0,165	✓	19,44 €
TAC1-10/SS	M10	13	15,8	150	255-376	1000	0,285	✓	24,81 €
TAC1-12/SS	M12	16,8	20,0	200	305-473	1400	0,515	-	38,04 €
TAC1-16/SS	M16	16,3	26,0	245	400-593	2300	1,110	-	77,15 €

*Depending on availability - Dimensions in mm

Our other products



FDS

Flexible drive shaft, Masterflex® Steel, with PVC casing



DER90

Stainless steel AC asynchronous motor 1.1 - 1.5kW, 1.1 to 1.5kW



UCF_PBT

Stainless steel/Polymer flanged bearing, Polymer and stainless steel



DOMI30

Connecting kits, XZ linking kit



P40

Worm and wheel gear reducer, up to 18 Nm



PSG125HC

Skive hobbled spur gears - precision range, Case hardened steel 20NCD2



PFC

Fixed rubber levelling foot, Levelling support for small parts



M0

Worm and wheel set, Bronze



DOMI30

Connecting kits, XY linking kit



CHM63

Worm and wheel gear reducer, up to 196 Nm



PCS25ECO

Chain sprocket - steel, 6.35mm



AT10courroie

AT type timing belt, AT10 Steel cored polyurethane

Complementary products



TAC

Rigging screw (hook/eye), Steel



TCC_SS

Stainless steel rigging screw (hook/hook), Stainless steel



MDR_SS

Stainless steel Dee shackle with eye bolt, Stainless steel



MLY_SS

Stainless steel bow shackle with eye bolt, Stainless steel