

Sta Stainless steel rigging screw with hook/eye

Turnbuckle

TACss

- Rigging screw with eye and hook



- Fitting component

- Material: stainless steel 316

Info.

- SWL: safe working load.

The Safe Working Load is calculated by dividing the breaking load by a factor of safety of 3

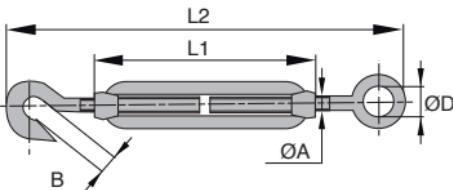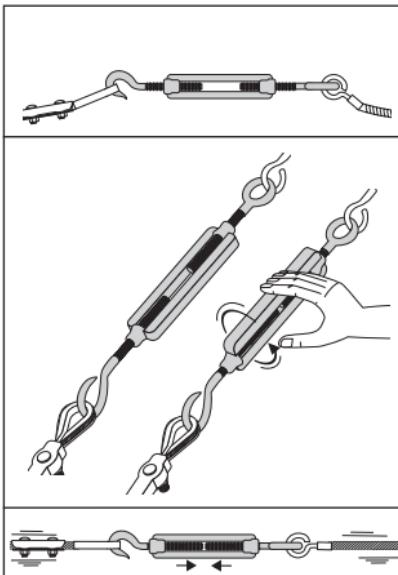

DISCOUNTS

Qty	1+	5+	10+	20+	30+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØA	B	ØD	L1	L2	SWL (kg)	Weight (kg)	Stock*	Price each 1 to 4
TAC1-05/SS	M5	9	8,3	71	122-179	180	0,046	✓	9,38 €
TAC1-06/SS	M6	9,5	10,0	90	160-228	360	0,076	✓	11,24 €
TAC1-08/SS	M8	11	12,0	120	210-303	650	0,165	✓	19,44 €
TAC1-10/SS	M10	13	15,8	150	255-376	1000	0,285	✓	24,81 €
TAC1-12/SS	M12	16,8	20,0	200	305-473	1400	0,515	-	38,04 €
TAC1-16/SS	M16	16,3	26,0	245	400-593	2300	1,110	-	77,15 €

*Depending on availability - Dimensions in mm

Our other products



CRM

Moulded nylon rack,
Nylon



INS150

Self tapping insert
with collar-coarse
thread, With collar-
coarse t...



MFBC

Flexible Bellows
coupling, Aluminium
and Bronze - with
clamping jaw



PTKss

Foot for the food
industry, Stainless
steel - 3-A standard



PO

Pull handle - Multi-
sector, Smooth hole



T5P_T10P

Connecting plate for T
type timing belts, T5



RPB

Ballscrew bearing
unit, Support



SLH

Horizontal toggle
clamp, Horizontal
Lever Clamp - steel



PP50

Worm and wheel gear
reducer, from 6.50 to
10000 Nm



SVG

Adjustable latch
clamp with strike



GG1

Ground spur gear,
Heat treated steel



BLHT50

Right angled gearbox,
from 11.50 to 30 Nm

Complementary products



TAC

Rigging screw
(hook/eye), Steel



TCC_SS

Stainless steel rigging
screw (hook/hook),
Stainless steel



MDR_SS

Stainless steel Dee
shackle with eye bolt,
Stainless steel



MLY_SS

Stainless steel bow
shackle with eye bolt,
Stainless steel