


- Adjustable feet
- Tilt angle : 25°
- Materials:
Base: polyethylene or polypropylene
Rod: mild steel, bright zinc plated

Simplest solution

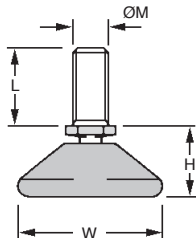

Economy range

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØM	L	W	H	Max. static load (kg)	Material	Stock*	Price each 1 to 5
TAD5008-25-1	M6	12,5	25	20	50	Polyethylene	✓	1,58 €
TAD5009-25-1	M6	25,0	25	20	50	Polyethylene	✓	1,76 €
TAD5010-25-1	M8	12,5	25	20	50	Polyethylene	✓	1,82 €
TAD5011-25-1	M8	25,0	25	20	50	Polyethylene	✓	1,90 €
TAD5013-25-1	M10	15,0	25	20	50	Polyethylene	✓	1,90 €
TAD5014-25-1	M10	37,5	25	20	50	Polyethylene	-	on request
TAD5015-25-1	M10	50,0	25	20	50	Polyethylene	✓	2,73 €
TAD5019-25-1	M12	50,0	25	20	50	Polyethylene	-	2,25 €
TAD5008-40-1	M6	12,5	40	20	100	Polyethylene	-	2,09 €
TAD5009-40-1	M6	25,0	40	20	100	Polyethylene	-	1,76 €
TAD5010-40-1	M8	12,5	40	20	100	Polyethylene	-	1,43 €
TAD5011-40-1	M8	25,0	40	20	100	Polyethylene	✓	2,21 €
TAD5013-40-1	M10	15,0	40	20	100	Polyethylene	-	1,98 €
TAD5014-40-1	M10	37,5	40	20	100	Polyethylene	✓	1,82 €
TAD5015-40-1	M10	50,0	40	20	100	Polyethylene	✓	2,14 €
TAD5019-40-1	M12	50,0	40	20	100	Polyethylene	✓	2,25 €
TAD5008-55-1	M6	12,5	55	20	100	Polypropylene	-	2,73 €
TAD5009-55-1	M6	25,0	55	20	100	Polypropylene	-	2,93 €
TAD5010-55-1	M8	12,5	55	20	100	Polypropylene	-	2,54 €
TAD5011-55-1	M8	25,0	55	20	100	Polypropylene	✓	2,59 €
TAD5013-55-1	M10	15,0	55	20	250	Polypropylene	-	2,64 €
TAD5014-55-1	M10	37,5	55	20	250	Polypropylene	✓	3,07 €
TAD5015-55-1	M10	50,0	55	20	250	Polypropylene	✓	3,46 €
TAD5019-55-1	M12	50,0	55	20	250	Polypropylene	✓	2,83 €

*Depending on availability - Dimensions in mm

Our other products




FDSQ

Flexible drive shaft,
Masterflex® Steel,
with PVC casing



BC3

 Panamech, Multi-
Beam stainless steel,
Stainless steel - with
clampin...




PRF-SCREEN-1

Screen support, Basic
support



CLB_M

 Die cast zinc clamping
lever - female, Zamak



H2

Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)



GMK17_BR

Clamp for guiding
profile, Rounded only
- double



WJUM10

Drylin® W bearing
block, Slide



VQTplq

Quarter-turn clamp
lock - Clamping plate,
Wall mounting



 
BSCf

Knurled torque knobs
- female, Knurled



CDR

Retaining cable for
ball pin, Retaining



RDERSS

Stainless steel manual
rigging screw,



S4

Chain sprocket-
stainless steel, 4mm

Complementary products



FAD

Threaded swivel feet,
Swivel feet without
anti-slip plate