

# Cylindrical roller thrust bearing



## TB8 Thrust bearing for high axial loads


- For use when thrust ball bearings are not suitable
- Comprised of two washers and a roller cage
- Material:  
Steel

### Info

- Not suitable for radial loads



For high axial loads

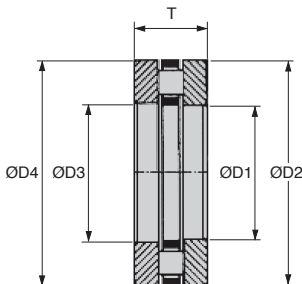

### DISCOUNTS

Qty	1+	4+	8+
Disc.	List	-15%	On request

Part number	ØA shaft	ØD1	ØD3	ØD4	ØD2	T	Load (kN)		Speed	Weight (kg)	Price each 1 to 3
							Dynamic (C)	Static (Co)	(rpm) lubricant oil		
TB81102TN	15	15	16	28	28	9	13,5	28,0	1350	0,024	24,72 €
TB81103TN	17	17	18	30	30	9	15,1	32,9	11400	0,027	24,72 €
TB81104TN	20	20	21	35	35	10	23,7	52,6	9500	0,037	26,75 €
TB81105TN	25	25	26	42	42	11	32,9	72,0	8000	0,053	29,21 €
TB81106TN	30	30	32	47	47	11	34,8	85,0	7100	0,057	30,71 €
TB81206TN	30	30	32	52	52	16	63,5	139,0	6650	0,123	43,61 €
TB81108TN	40	40	42	60	60	13	55,0	147,5	5700	0,105	38,38 €
TB81110TN	50	50	52	70	70	14	60,7	167,0	4500	0,140	46,53 €
TB81112TN	60	60	62	85	85	17	102,1	309,5	3800	0,266	65,51 €
TB81114TN	70	70	72	105	105	27	186,0	549,7	3100	0,332	78,92 €
TB81118TN	90	90	92	120	120	22	140,6	459,0	2550	0,620	131,97 €

Dimensions in mm

## Our other products



G-ECO

Eco range Spur gear,  
Steel C45



BPLF

Ball transfer unit light  
duty, Light



RFVcap

Stainless steel  
protective cover,  
Closed protective  
cover



PRF-SCREEN-1

Screen support, Basic  
support



DER80

Stainless steel AC  
asynchronous motor  
0.55 - 0.75kW, 0.55 to  
0.75kW



AZY

Cylindrical elasto  
mount, Steel



SLB

Indexing plunger,  
steel class 5.8



PTAF100-PAMF100

Articulated fixable  
foot with pressed  
base Ø100, Ø 100



GGB

Female wing knob,  
With blind thread




ACL-FPA

Panel mounting block  
for aluminium  
structures, Support



HBM

Adjustment bushing  
for half-rail guide,  
Adjustment bushing

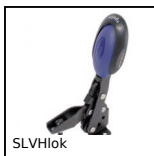

SLVHlok

Vertical toggle clamp,  
Vertical toggle clamp /  
horizontal foot

## Complementary products



TBbutee

Axial thrust bearing,  
Steel balls