

# Cylindrical roller thrust bearing



## TB8 Thrust bearing for high axial loads


- For use when thrust ball bearings are not suitable
- Comprised of two washers and a roller cage
- Material:  
Steel

### Info

- Not suitable for radial loads



For high axial loads

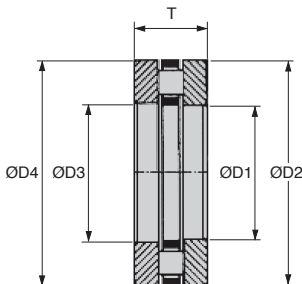


### DISCOUNTS

Qty	1+	4+	8+
Disc.	List	-15%	On request

Part number	ØA shaft	ØD1	ØD3	ØD4	ØD2	T	Load (kN)		Speed (rpm)	Weight (kg)	Price each 1 to 3
							Dynamic (C)	Static (Co)			
TB81102TN	15	15	16	28	28	9	13,5	28,0	1350	0,024	24,72 €
TB81103TN	17	17	18	30	30	9	15,1	32,9	11400	0,027	24,72 €
TB81104TN	20	20	21	35	35	10	23,7	52,6	9500	0,037	26,75 €
TB81105TN	25	25	26	42	42	11	32,9	72,0	8000	0,053	29,21 €
TB81106TN	30	30	32	47	47	11	34,8	85,0	7100	0,057	30,71 €
TB81206TN	30	30	32	52	52	16	63,5	139,0	6650	0,123	43,61 €
TB81108TN	40	40	42	60	60	13	55,0	147,5	5700	0,105	38,38 €
TB81110TN	50	50	52	70	70	14	60,7	167,0	4500	0,140	46,53 €
TB81112TN	60	60	62	85	85	17	102,1	309,5	3800	0,266	65,51 €
TB81114TN	70	70	72	105	105	27	186,0	549,7	3100	0,332	78,92 €
TB81118TN	90	90	92	120	120	22	140,6	459,0	2550	0,620	131,97 €

Dimensions in mm
 
## Our other products



AC

Strike for toggle latch,  
15mm



PTA100

Articulated levelling  
foot, pressed base  
Ø100, Ø 100



PRF JL6

Lip seal for panel,  
Door seal - Ø 6mm




G-ECO

Eco range Spur gear,  
Steel C45



PM4

 Worm and wheel set,  
Hardened steel



LVTMFC

Device for controlling  
limit switches, For  
mini-actuator LVT



APB\_T

Adjusting rod for  
clamp - Female, Bored




MDPOT

Potentiometer,



DOMI120

 Domino 120  
adjustable slide, Slide  
DOMILINE 120 with



BLHM30

Right angled gearbox,  
double output shafts,  
up to 4.4 Nm



BDPR

Holding arm, Rigid



NPTF30

Spacer for tube  
carrier, Fixing  
accessory Ø14 to Ø20

## Complementary products



TBbutee

Axial thrust bearing,  
Steel balls