

Cylindrical roller thrust bearing



TB8 Thrust bearing for high axial loads


- For use when thrust ball bearings are not suitable
- Comprised of two washers and a roller cage
- Material:
Steel

Info

- Not suitable for radial loads



For high axial loads

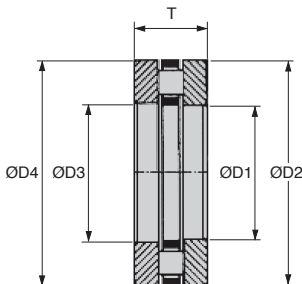

DISCOUNTS

Qty	1+	4+	8+
Disc.	List	-15%	On request

Part number	ØA shaft	ØD1	ØD3	ØD4	ØD2	T	Load (kN)		Speed (rpm)	Weight (kg)	Price each 1 to 3
							Dynamic (C)	Static (Co)	lubricant oil		
TB81102TN	15	15	16	28	28	9	13,5	28,0	1350	0,024	24,72 €
TB81103TN	17	17	18	30	30	9	15,1	32,9	11400	0,027	24,72 €
TB81104TN	20	20	21	35	35	10	23,7	52,6	9500	0,037	26,75 €
TB81105TN	25	25	26	42	42	11	32,9	72,0	8000	0,053	29,21 €
TB81106TN	30	30	32	47	47	11	34,8	85,0	7100	0,057	30,71 €
TB81206TN	30	30	32	52	52	16	63,5	139,0	6650	0,123	43,61 €
TB81108TN	40	40	42	60	60	13	55,0	147,5	5700	0,105	38,38 €
TB81110TN	50	50	52	70	70	14	60,7	167,0	4500	0,140	46,53 €
TB81112TN	60	60	62	85	85	17	102,1	309,5	3800	0,266	65,51 €
TB81114TN	70	70	72	105	105	27	186,0	549,7	3100	0,332	78,92 €
TB81118TN	90	90	92	120	120	22	140,6	459,0	2550	0,620	131,97 €

Dimensions in mm

Our other products



PSG05
Spur gear - precision range, Case hardened steel 20NCD2



LRX
Linear roller slide, Chariot - from 9410 N to 101000 N



PRF_ROUL
Castor for aluminium profile, No brake



PR85
Articulated foot Ø83, Ø 83



CM_CO
Tools Hygienic Usit® and Hygienic Design®, Protective inserts for ...



HLUT
Spoked handwheel with handle, Aluminium



EMS
Stainless steel knurled thumb nut, Knurled



PENC
Recessed handle, clip-in



TSRTC
Stem support for castor, For swivel castor with central



M1
Worm and wheel set, Hardened steel



SKM
Hexagonal steel nut, Steel - 1 thread



CQA20
Accessory for adjustment slide-system, 20

Complementary products



TBbutee
Axial thrust bearing, Steel balls