

Cylindrical roller thrust bearing



TB8 Thrust bearing for **high** axial loads


- For use when thrust ball bearings are not suitable
- Comprised of two washers and a roller cage
- Material:
Steel

Info

- Not suitable for radial loads



For high axial loads

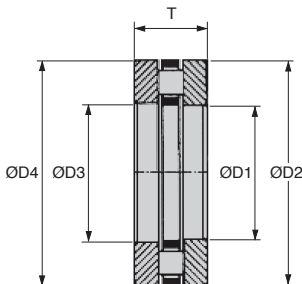

DISCOUNTS

Qty	1+	4+	8+
Disc.	List	-15%	On request

Part number	ØA shaft	ØD1	ØD3	ØD4	ØD2	T	Load (kN)		Speed	Weight (kg)	Price each 1 to 3
							Dynamic (C)	Static (Co)	(rpm) lubricant oil		
TB81102TN	15	15	16	28	28	9	13,5	28,0	1350	0,024	24,72 €
TB81103TN	17	17	18	30	30	9	15,1	32,9	11400	0,027	24,72 €
TB81104TN	20	20	21	35	35	10	23,7	52,6	9500	0,037	26,75 €
TB81105TN	25	25	26	42	42	11	32,9	72,0	8000	0,053	29,21 €
TB81106TN	30	30	32	47	47	11	34,8	85,0	7100	0,057	30,71 €
TB81206TN	30	30	32	52	52	16	63,5	139,0	6650	0,123	43,61 €
TB81108TN	40	40	42	60	60	13	55,0	147,5	5700	0,105	38,38 €
TB81110TN	50	50	52	70	70	14	60,7	167,0	4500	0,140	46,53 €
TB81112TN	60	60	62	85	85	17	102,1	309,5	3800	0,266	65,51 €
TB81114TN	70	70	72	105	105	27	186,0	549,7	3100	0,332	78,92 €
TB81118TN	90	90	92	120	120	22	140,6	459,0	2550	0,620	131,97 €

Dimensions in mm

Our other products



DOMI80

Accessories, Clamping lever



BPLF

Ball transfer unit light duty, Light



BPVM

Miniature ball transfer unit, Miniature to screw



ACM_AZ

Mounting bracket for bonnet fastener, Hook



SSG2_304L

Stainless steel spur gear, Stainless steel 304L



PCLA_M

Technopolymer clamping lever - female, Plastic



VPSS

Small 6 lobe threaded handle - male, Duroplast - Stainless steel



PRF-SCREEN-4

Screen support, Support with 4 axes of rotation



SERB

Cam latch, Cam latch



PENV

Recessed handle, screw fixing



PFM

Fixed levelling foot, Flanged plate



EFSM

Igubal® flange bearing, Polymer

Complementary products



TBbutee

Axial thrust bearing, Steel balls