


Mini leadscrew table with metric thread



TBL

Allows X-Y-Z movements



- Mini table with metric leadscrew for manual operation
- Metric leadscrew M6x1 right hand
- Guided by 2 steel rods on 4 brass bearings (no wiper joints)
- Axial precision < 0.10 mm
- With position indicator and button
- Material:
Aluminium, steel
- Working temperature range: +5° to +80°C

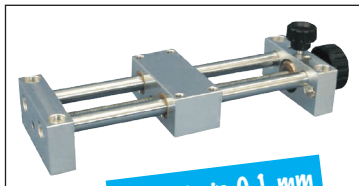

Accurate to 0.1 mm

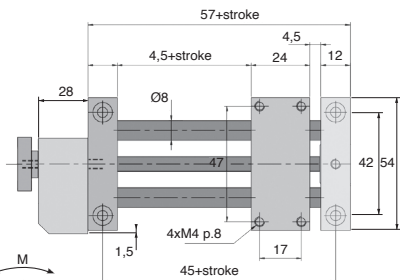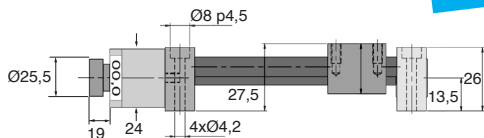

With Z Option :
fixed via front plate

 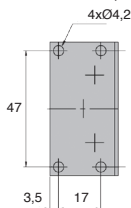

DISCOUNTS

Qty	1+	2+	3+
Disc.	List	-10%	On request

Part number	Stroke	Max supported load (kg)	Admissible torque (Nm)	Static force F (daN)	Weight (kg)	Price each
Table horizontal X + Y axes						
TBL-50-CV	50	1	0,50	6,00	0,25	297,76 €
TBL-100-CV	100	1	0,50	6,00	0,30	299,47 €
Table vertical Z axis						
TBL-50Z-CV	50	0,5	0,50	6,00	0,25	302,60 €
TBL-100Z-CV	100	0,5	0,50	6,00	0,30	304,33 €



Dimensions in mm

Mini leadscrew table with metric thread


TBL Base plate for X-Y-Z configurations

- **Connection plate**
- To be screwed to end plates
- Countersunk mounting holes
- **Materials:**
Anodised aluminium
with plated steel screws


XY configuration:
2 standard tables
1 base plate

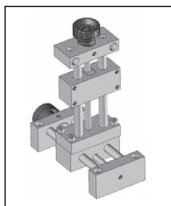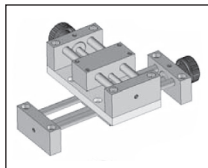

YZ configuration:
1 standard table
1 Z axis table
4 CHC screws (M4 x 20)

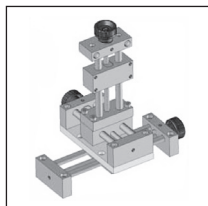

XYZ configuration:
2 standard tables
1 Z axis table
1 base plate
4 CHC screws (M4 x 20)

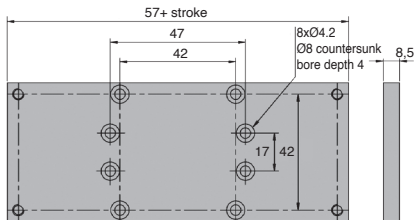

DISCOUNTS

Qty	1+	2+	3+
Disc.	List	-10%	On request

Part number	For stroke (mm)	Price each
TBL-XY50	50	34,02 €
TBL-XY100	100	36,83 €

Dimensions in mm

Our other products



GAC
Lock for latch clamp,
Strike plate



PRF_BM
Base support plate for
aluminium profile,
Central base fixation



WSRM
Cylindrical polymer
nut, Polymer
(Iglidur®) - 1 thread



CRM
Moulded nylon rack,
Nylon



PTA150
Articulated levelling
foot, pressed base
Ø150, Ø 150



LRRss
Latch, Spring loaded
latch - stainless steel



F7-SF-SM
Multifunction display,
Mounting bracket for
front mounting



MSP38
Masterplate®
glueable insert Ø38,
Cylindrical Ø38 with
tapped ins...



CAP881
Side flexing slim slat
top chain stainless
steel, Narrow range



PF45
Worm and wheel gear
reducer, up to 40 Nm

 


CHINV
Invisible hinge,
Invisible - Opening up
to 90°



OPFL_OPPM
Numerical counter
accessories, Locking
clamp

Complementary products



TBL
Mini leadscrew table
with metric thread,
Base plate



TBEBASE10
Economic mini-table
with trapezoidal
leadscrew, 1kg



TBE12
Economic mini-table
with trapezoidal
leadscrew, 2kg



TBE16
Economic mini-table
with trapezoidal
leadscrew, 5kg