


Mini leadscrew table with metric thread



TBL

Allows X-Y-Z movements



- Mini table with metric leadscrew for manual operation
- Metric leadscrew M6x1 right hand
- Guided by 2 steel rods on 4 brass bearings (no wiper joints)
- Axial precision < 0.10 mm
- With position indicator and button
- Material:
Aluminium, steel
- Working temperature range: +5° to +80°C

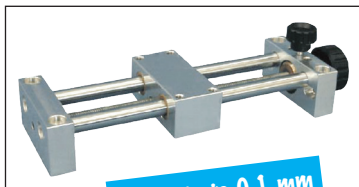

Accurate to 0.1 mm

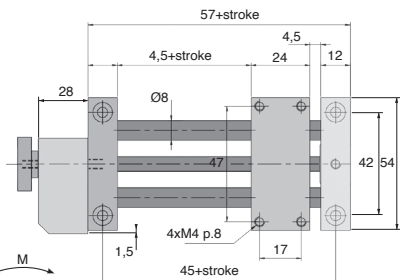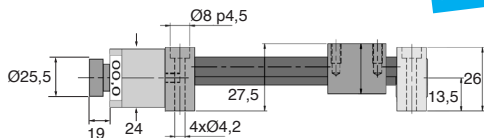

With Z Option :
fixed via front plate

 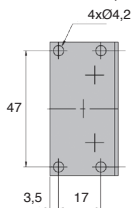

DISCOUNTS

Qty	1+	2+	3+
Disc.	List	-10%	On request

Part number	Stroke	Max supported load (kg)	Admissible torque (Nm)	Static force F (daN)	Weight (kg)	Price each
Table horizontal X + Y axes						
TBL-50-CV	50	1	0,50	6,00	0,25	297,76 €
TBL-100-CV	100	1	0,50	6,00	0,30	299,47 €
Table vertical Z axis						
TBL-50Z-CV	50	0,5	0,50	6,00	0,25	302,60 €
TBL-100Z-CV	100	0,5	0,50	6,00	0,30	304,33 €



Dimensions in mm

Mini leadscrew table with metric thread


TBL Base plate for X-Y-Z configurations

- **Connection plate**
- To be screwed to end plates
- Countersunk mounting holes
- **Materials:**
Anodised aluminium
with plated steel screws


XY configuration:
2 standard tables
1 base plate

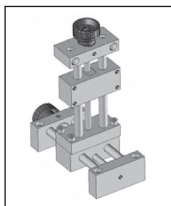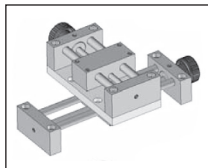

YZ configuration:
1 standard table
1 Z axis table
4 CHC screws (M4 x 20)

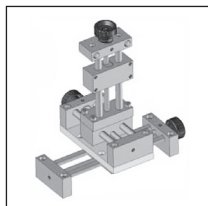

XYZ configuration:
2 standard tables
1 Z axis table
1 base plate
4 CHC screws (M4 x 20)

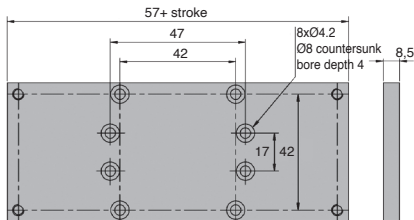

DISCOUNTS

Qty	1+	2+	3+
Disc.	List	-10%	On request

Part number	For stroke (mm)	Price each
TBL-XY50	50	34,02 €
TBL-XY100	100	36,83 €

Dimensions in mm

Our other products




BTESS

Universal stainless steel arm for tensioner, For use in hostile envi...



BUH77

 Motor-gearbox 12V and 24V DC, from 0.1 to 2 Nm



MRS

Stainless steel metric section rack, Stainless steel



PGM52-M4

Pull handle, Brass



MHX

Hexagonal threaded sleeve, Hexagonal - steel



VPSS

Small 6 lobe threaded handle - male, Duroplast - Stainless steel



PAMF120

Articulated fixable foot, pressed bolt-down base \varnothing 120, \varnothing 120




VTH

Hexagonal headed bolts, Steel class 8.8



CHMR40

 Worm and wheel gear reducer, up to 57 Nm



M1

Worm and wheel set, Machined plastic (delrin)



SH4

 
Parallel axis helical gear, Steel 20NCD2



GARDLL

Mounting sleeve for lock pin, Nickel-plated steel or Stainless steel

Complementary products



TBL

Mini leadscrew table with metric thread, Base plate



TBEBASE10

Economic mini-table with trapezoidal leadscrew, 1kg



TBE12

Economic mini-table with trapezoidal leadscrew, 2kg



TBE16

Economic mini-table with trapezoidal leadscrew, 5kg