
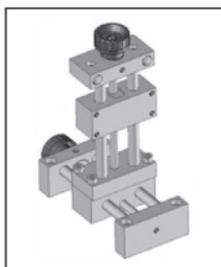



## TBL Base plate for X-Y-Z configurations

- **Connection plate**
- To be screwed under end plates
- Countersunk mounting holes
- **Materials:**  
Anodised aluminium  
with plated steel screws


**XY configuration:**  
2 standard tables  
1 base plate

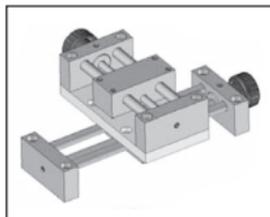

**YZ configuration:**  
1 standard table  
1 Z axis table  
4 CHC screws (M4 x 20)

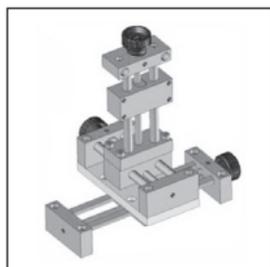

**XYZ configuration:**  
2 standard tables  
1 Z axis table  
1 base plate  
4 CHC screws (M4 x 20)

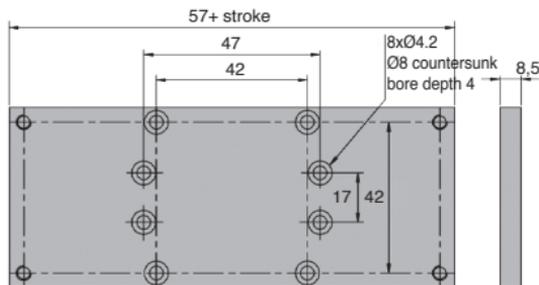

### DISCOUNTS

Qty	1+	2+	3+
Disc.	List	-10%	On request

Part number	For stroke (mm)	Price each
TBL-XY50	50	41,90 €
TBL-XY100	100	45,37 €

Dimensions in mm



# Mini leadscrew table with metric thread



Allows X-Y-Z movements

TBL


- Mini table with metric leadscrew for manual operation
- Metric leadscrew M6x1 right hand
- Guided by 2 steel rods on 4 brass bearings (no wiper joints)
- Axial precision < 0.10 mm
- With position indicator and button
- Material:  
Aluminium, steel
- Working temperature range: +5° to +80°C



Accurate to 0.1 mm

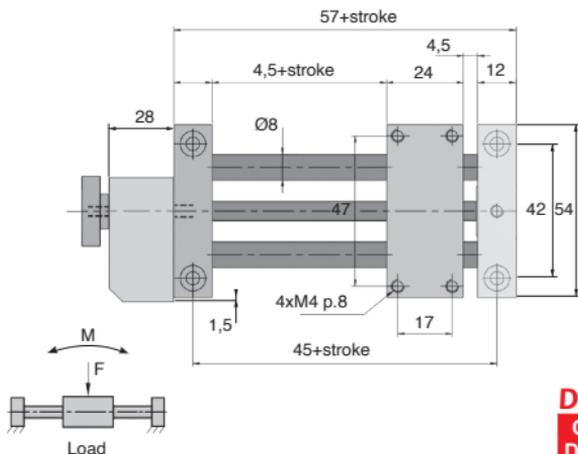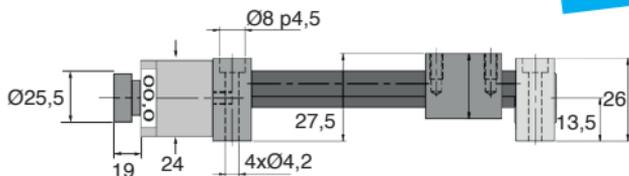

With Z Option :  
fixed via front plate

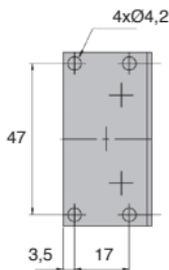

## DISCOUNTS

Qty	1+	2+	3+
Disc.	List	-10%	On request

Part number	Stroke	Max supported load (kg)	Admissible torque (Nm)	Static force F (daN)	Weight (kg)	Price each
<b>Table horizontal X + Y axes</b>						
TBL-50-CV	50	1	0,50	6,00	0,25	334,88 €
TBL-100-CV	100	1	0,50	6,00	0,30	336,80 €
<b>Table vertical Z axis</b>						
TBL-50Z-CV	50	0,5	0,50	6,00	0,25	340,32 €
TBL-100Z-CV	100	0,5	0,50	6,00	0,30	342,27 €

Dimensions in mm