


Mini leadscrew table with metric thread



TBL

Allows X-Y-Z movements


- Mini table with metric leadscrew for manual operation
- Metric leadscrew M6x1 right hand
- Guided by 2 steel rods on 4 brass bearings (no wiper joints)
- Axial precision < 0.10 mm
- With position indicator and button
- Material:
Aluminium, steel
- Working temperature range: +5° to +80°C

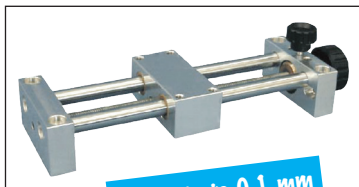

Accurate to 0.1 mm

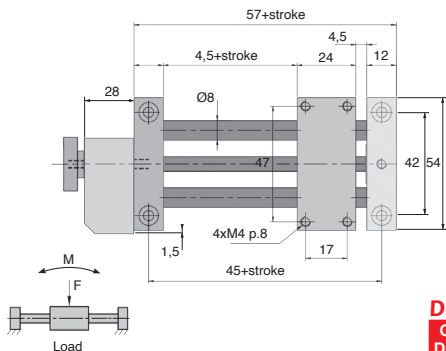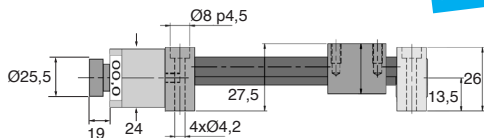

With Z Option :
fixed via front plate

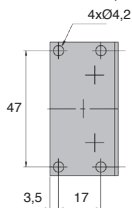

DISCOUNTS

Qty	1+	2+	3+
Disc.	List	-10%	On request

Part number	Stroke	Max supported load (kg)	Admissible torque (Nm)	Static force F (daN)	Weight (kg)	Price each
Table horizontal X + Y axes						
TBL-50-CV	50	1	0,50	6,00	0,25	297,76 €
TBL-100-CV	100	1	0,50	6,00	0,30	299,47 €
Table vertical Z axis						
TBL-50Z-CV	50	0,5	0,50	6,00	0,25	302,60 €
TBL-100Z-CV	100	0,5	0,50	6,00	0,30	304,33 €

Dimensions in mm

Mini leadscrew table with metric thread

TBL Base plate for X-Y-Z configurations

- Connection plate



- To be screwed to end plates
- Countersunk mounting holes

- Materials:

Anodised aluminium
with plated steel screws


XY configuration:

- 2 standard tables
- 1 base plate

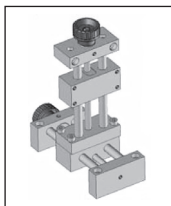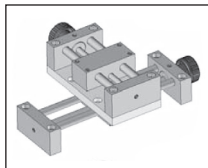


YZ configuration:

- 1 standard table
- 1 Z axis table
- 4 CHC screws (M4 x 20)

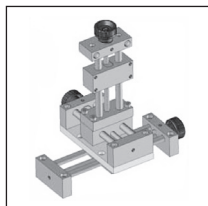

XYZ configuration:

- 2 standard tables
- 1 Z axis table
- 1 base plate
- 4 CHC screws (M4 x 20)

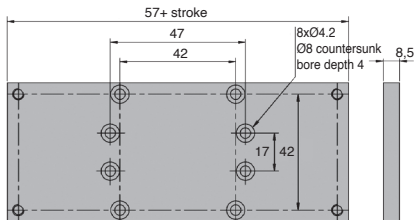

DISCOUNTS

Qty	1+	2+	3+
Disc.	List	-10%	On request

Part number	For stroke (mm)	Price each
TBL-XY50	50	34,02 €
TBL-XY100	100	36,83 €

Dimensions in mm

Our other products



CHB

Reaction arm, CHB gear reducers reaction arm



H3

Crossed helical gear crossed axis at 90°, Steel 20NCD2



CHT

Asynchronous AC motor, 0.09kW



RFK28C

Hypoid gearbox - Stainless steel, up to 130 Nm



MEB

Moulded plastic bevel gear (nylon), 1:1



PPS

Lifting ring, Universal threaded



PRS100

Stainless steel articulated foot Ø100, Ø 100



CHTRP

Single and dual output gearboxes, Up to 28,8 Nm



NSKB

Drylin® Rail end cap, Rail end cap



RTE

Rotex®, jaw coupling, steel



DB

Steel bevel gear, 2:1



PRF_ROUL_F

Castor for aluminium profile, With brake

Complementary products



TBL

Mini leadscrew table with metric thread, 1kg