

# Manual **lifting** tables








## TBV1 For vertical strokes - Ø 12 mm column

### Manually operated leadscrew table

- Right handed leadscrew TR10x2
- 12 mm diameter guide rods
- Fixed by the extremities for vertical or off-centred applications
- Guided by 2 steel rods on 4 brass bearings (no wiper joints)
- With position indicator and button
- Axial precision <math><0.10\text{ mm}</math>
- Material:  
Aluminium, steel
- Working temperature range:  
 $+5^\circ$  to  $+80^\circ\text{ C}$

Accurate to 0.1 mm

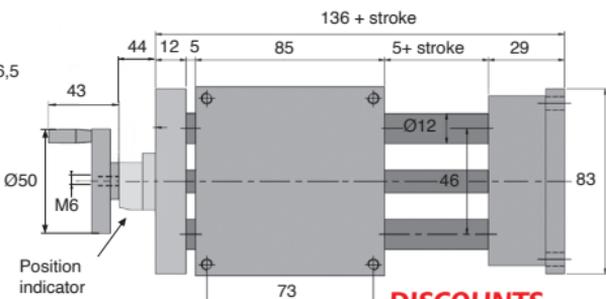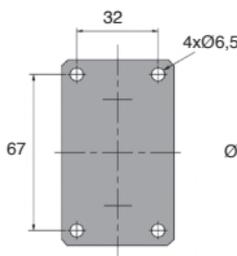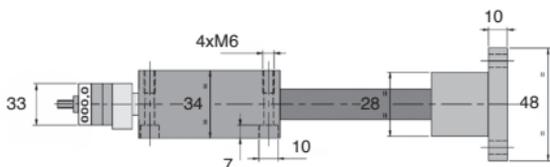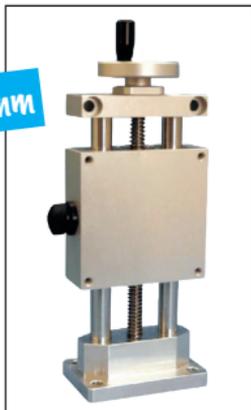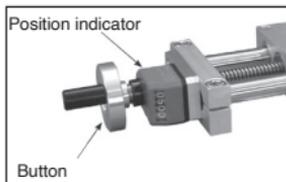

### DISCOUNTS

Qty	1+	2+	3+
Disc.	List -10%	On request	

Part number	Stroke	Leadscrew	Max supported load (kg)	Moving torque on hand wheel (Nm)	Indication for 1 rev	Weight* (kg)	Price each
TBV1-50-CV	50	TR10x2	3	0,30	002,0	1,20	557,52 €
TBV1-100-CV	100	TR10x2	3	0,30	002,0	1,31	557,52 €
TBV1-150-CV	150	TR10x2	3	0,30	002,0	1,42	561,56 €
TBV1-200-CV	200	TR10x2	3	0,30	002,0	1,53	561,56 €
TBV1-300-CV	300	TR10x2	3	0,30	002,0	1,75	565,63 €

\*Weight without hand wheel or indicator - Dimensions in mm








# Manual lifting tables

## For vertical strokes – Ø16 mm column TBV2

- **Manually operated leadscrew table**
- Right handed leadscrew TR12x3
- 16mm diameter guide rods
- Fixed by the extremities for vertical or off-centred applications
- Guided by 2 steel rods on 4 brass bearings (no wiper joints)
- With position indicator and hand wheel
- Axial precision <math><0.10\text{ mm}</math>
- Material:  
Aluminium, steel
- Working temperature range:  
 $+5^{\circ}$  to  $+80^{\circ}\text{C}$

Accurate to 0.1 mm

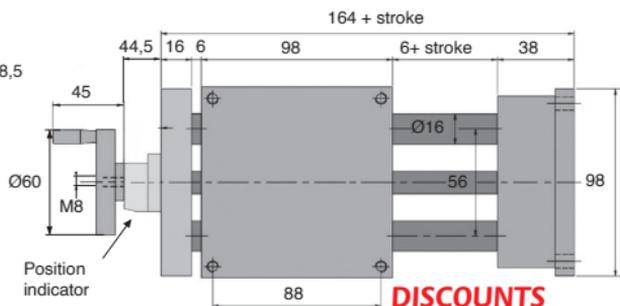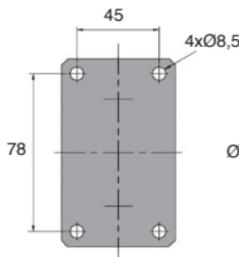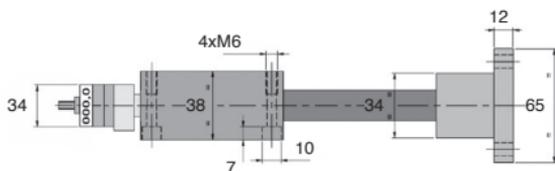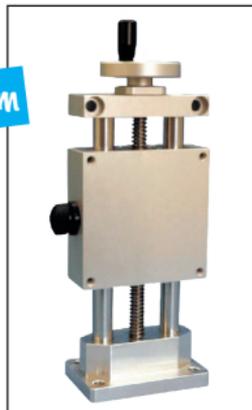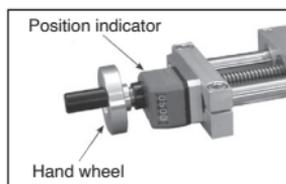

### DISCOUNTS

Qty	1+	2+	3+
Disc.	List -10%	On request	

Part number	Stroke	Leadscrew	Max supported load (kg)	Moving torque on hand wheel (Nm)	Indication for 1 rev	Weight* (kg)	Price each
TBV2-50-CV	50	TR12x3	7	0,45	003,0	2,11	609,05 €
TBV2-100-CV	100	TR12x3	7	0,45	003,0	2,29	609,05 €
TBV2-150-CV	150	TR12x3	7	0,45	003,0	2,47	615,66 €
TBV2-200-CV	200	TR12x3	7	0,45	003,0	2,65	615,66 €
TBV2-300-CV	300	TR12x3	7	0,45	003,0	3,01	622,28 €

\*Weight without hand wheel or indicator - Dimensions in mm






# Manual **lifting** tables



## TBV3 For vertical strokes – Ø20 mm column

- **Manually operated leadscrew table**
- Right handed leadscrew TR16x4
- 20 mm diameter guide rods
- Fixed by the extremities for vertical or off-centred applications
- With position indicator and hand wheel
- Axial precision <math><0.10\text{ mm}</math>
- Material: Aluminium, steel
- Working temperature range: +5 to +80 °C

**Accurate to 0.1 mm**

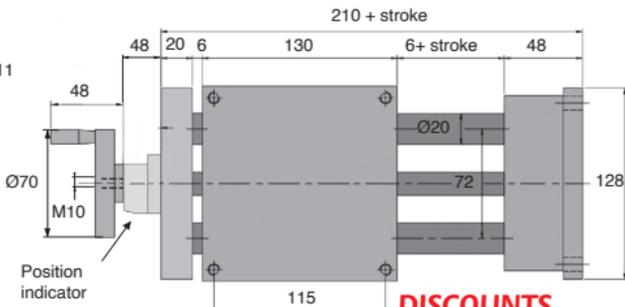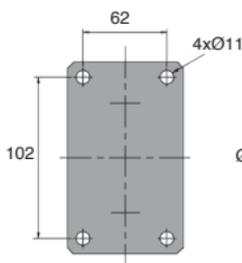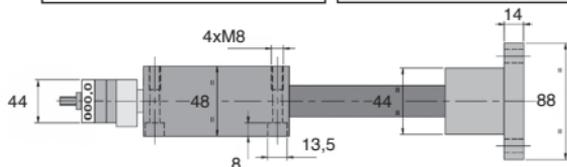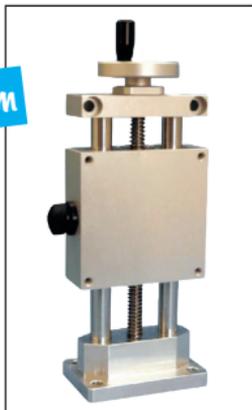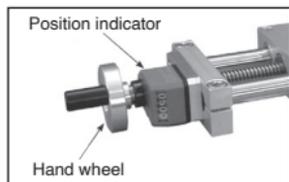

### DISCOUNTS

Qty	1+	2+	3+
Disc.	List -10%	On request	

Part number	Stroke	Leadscrew	Max supported load (kg)	Moving torque on hand wheel(Nm)	Indication for 1 rev	Weight* (kg)	Price each
TBV3-50-CV	50	TR16x4	12	0,60	004,0	4,12	738,49 €
TBV3-100-CV	100	TR16x4	12	0,60	004,0	4,43	738,49 €
TBV3-150-CV	150	TR16x4	12	0,60	004,0	4,74	747,33 €
TBV3-200-CV	200	TR16x4	12	0,60	004,0	5,05	747,33 €
TBV3-300-CV	300	TR16x4	12	0,60	004,0	5,67	756,12 €

\*Weight without hand wheel or indicator - Dimensions in mm





# Manual lifting tables

## For vertical strokes - Ø25 mm column TBV4

### - Manually operated leadscrew table

- Right handed leadscrew TR16x4
- 25 mm diameter guide rods
- Fixed by the extremities for vertical or off-centred applications
- Guided by 2 steel rods on 4 brass bearings (no wiper joints)
- Axial precision (in locked position) <math><0.05\text{ mm}</math>
- With position indicator and hand wheel
- Axial precision <math><0.10\text{ mm}</math>
- Material: Aluminium, steel
- Working temperature range: +5 to + 80°C

Accurate to 0.1 mm


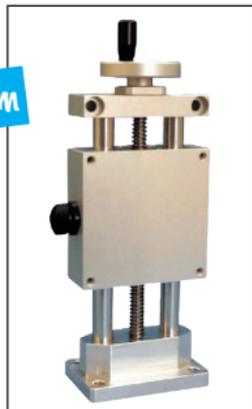
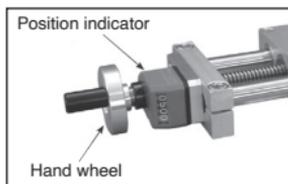


### Option

- Handwheel with angular gearbox, contact us



### Option angular gearbox

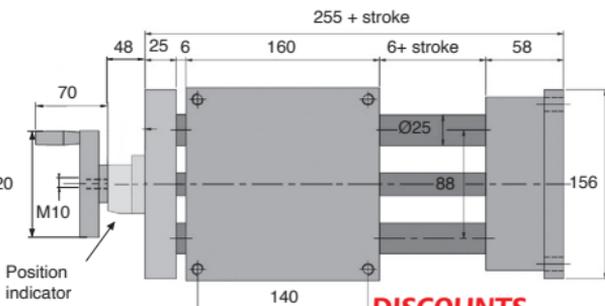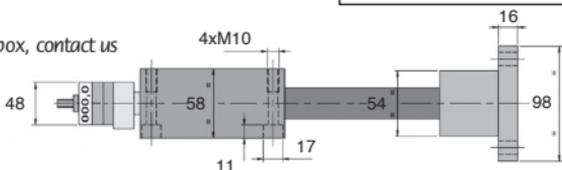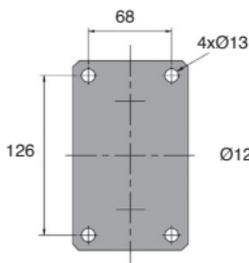

### DISCOUNTS

Qty	1+	2+	3+
Disc.	List -10%	On request	

Part number	Stroke	Leadscrew	Max supported load (kg)	Moving torque on hand wheel(Nm)	Indication for 1 rev	Weight* (kg)	Price each
TBV4-50-CV	50	TR16x4	20	1,25	004,0	7,28	918,64 €
TBV4-100-CV	100	TR16x4	20	1,25	004,0	7,73	918,64 €
TBV4-150-CV	150	TR16x4	20	1,25	004,0	8,18	930,07 €
TBV4-200-CV	200	TR16x4	20	1,25	004,0	8,63	930,07 €
TBV4-300-CV	300	TR16x4	20	1,25	004,0	9,53	941,50 €

\*Weight without hand wheel or indicator - Dimensions in mm