

Stainless steel rigging screw with 2 hooks



Turnbuckle

TCCss

- Rigging screw with two hooks
- Fitting component
- Material:
Clamp : stainless steel 316

Info.

- SWL: safe working load.
The Safe Working Load is calculated by dividing the breaking load by a factor of safety of 3

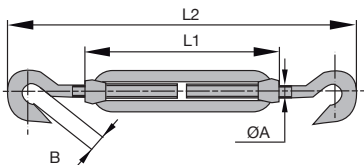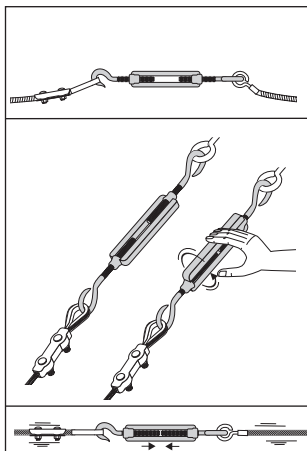


DISCOUNTS

Qty	1+	5+	10+	20+	30+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØA	B	L1	L2	SWL (kg)	Weight (kg)	Stock*	Price each 1 to 4
TCC1-05/SS	M5	9	71	128-184	180	0,045	✓	9,38 €
TCC1-06/SS	M6	10	90	160-228	360	0,075	✓	11,24 €
TCC1-08/SS	M8	9	120	215-309	650	0,165	✓	19,44 €
TCC1-10/SS	M10	12	150	265-380	1000	0,280	-	24,81 €
TCC1-12/SS	M12	15	200	310-480	1400	0,510	-	38,04 €
TCC1-16/SS	M16	16	243	400-594	2300	1,060	-	77,15 €

*Depending on availability - Dimensions in mm

 Our other products



RDE-W
Sealing washer
Hygienic Usit®,
Stainless steel - White
EPDM



NSU
Universal 90° support
clamp, Universal 90°
support clamp



BEAS
Knob star grip
antistatic, Star, anti-
static



SH2
Parallel axis helical
gear, Machined plastic
(delrin)



MDB_MTB
Moulded plastic bevel
gear (nylon), 3:1



PTA150
Articulated levelling
foot, pressed base
Ø150, Ø 150



BPF150
Pressed stainless
steel flange bearing,
Stainless steel



ZDB
Machined plastic
bevel gear , 2:1



CHT
Asynchronous AC
motor , 0.09kW



DOMI50
Connecting kits, XY
linking kit



HDSS
Needle roller double
universal joint -
Stainless steel, Heavy



ACLALF
Adjustable foot for
aluminium profile,
Ideal for workstations

Complementary products



TCC
Rigging screw
(hook/hook), Steel



TAC_SS
Stainless steel rigging
screw (hook/eye),
Stainless steel



MDR_SS
Stainless steel Dee
shackle with eye bolt,
Stainless steel



MLY_SS
Stainless steel bow
shackle with eye bolt,
Stainless steel