

Stainless steel rigging screw with 2 hooks



Turnbuckle

TCCss

- Rigging screw with two hooks
- Fitting component
- Material:
Clamp : stainless steel 316

Info.

- SWL: safe working load.
The Safe Working Load is calculated by dividing the breaking load by a factor of safety of 3

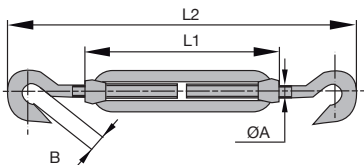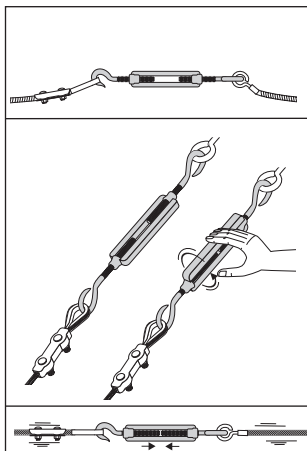

DISCOUNTS

Qty	1+	5+	10+	20+	30+
Disc. List	-5%	-10%	-15%	On request	

Part number	ØA	B	L1	L2	SWL (kg)	Weight (kg)	Stock*	Price each 1 to 4
TCC1-05/SS	M5	9	71	128-184	180	0,045	✓	9,38 €
TCC1-06/SS	M6	10	90	160-228	360	0,075	✓	11,24 €
TCC1-08/SS	M8	9	120	215-309	650	0,165	✓	19,44 €
TCC1-10/SS	M10	12	150	265-380	1000	0,280	-	24,81 €
TCC1-12/SS	M12	15	200	310-480	1400	0,510	-	38,04 €
TCC1-16/SS	M16	16	243	400-594	2300	1,060	-	77,15 €

*Depending on availability - Dimensions in mm

Our other products



FF50
Offset spur gear
reducer, from 111 to
425 Nm



DOG316
Motor-gearbox 12V
and 24V DC, from 1.5
to 2 Nm



HLU
Spoked handwheel
without handle,
Aluminium



EHD04
Internal epicyclic
servo reducers, from
3.4 to 7 Nm



CHARcav
Spring hinge, to install



MDB_MTB
Moulded plastic bevel
gear (nylon), 3:1



GLT3E-58
Telescopic drawer,



SLV
Vertical toggle clamp,
Vertical Lever Clamp -
steel



WJRM
Drylin® W hybrid
bearing block, Hybrid
bearings



DOMI120
Accessories, Plate



P60
Worm and wheel gear
reducer, up to 118
Nm



FBL6000_K13
Brush strip per meter
PP fibres Ø0.2, Black
striated polypropylene
...

Complementary products



TCC
Rigging screw
(hook/hook), Steel



TAC_SS
Stainless steel rigging
screw (hook/eye),
Stainless steel



MDR_SS
Stainless steel Dee
shackle with eye bolt,
Stainless steel



MLY_SS
Stainless steel bow
shackle with eye bolt,
Stainless steel