

# T-Clip - Aluminium profile attachment

## TCL-PD

### Document holder

#### - Document holder

 
- Description: The document holder has 2 tabs that allow from 1 to 5 sheets to be supported on an aluminium profile

#### Advantages

- The documents can be inserted or removed very quickly

#### Info.

- Not sold individually please contact-us for details



#### DISCOUNTS

Qty	1+	20+	50+
Disc.	List	-5%	On request

Part number	Material	Dimensions	Compatibility	Capacity	Stock*	Price each 1 to 19
TCL-PD	POM	50x32x10	8 and 10mm T-Clip	1 à 5 sheet	4	2,55 €

Dimensions in mm

## TCL-PC

### Cable support


- Description : A cable holder quipped with 2 base plates that makes it possible to run 2 electrical cables along an aluminium profile.

#### Advantages

- Quick and easy to install
- Cables can be installed both vertically as well as horizontally
- No longer necessary to tie anything around the profile to attach a cable

#### Info.

- Not sold individually please contact-us for details

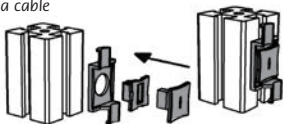

#### DISCOUNTS

Qty	1+	20+	50+
Disc.	List	-5%	On request

Part number	Material	Dimensions	Compatibility	Capacity	Stock*	Price each 1 to 19
TCL-PC	PA6	54x24x9	8 and 10mm T-Clip	2 cable support	-	2,11 €

Dimensions in mm

## Our other products



BH01  
Single housed bearing, Bearing fitted with adhesive



G-ECO  
Eco range Spur gear, Steel C45




AT5M AT10M  
AT type timing belt per metre, AT5 Steel cored polyurethane



PF70  
Worm and wheel gear reducer, up to 164 Nm



SH2  
Parallel axis helical gear, Steel 20NCD2

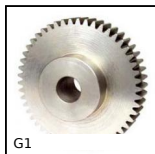

G1  
Steel spur gear, Steel 20NCD2



BLHB60  
Right angled gearbox, bored shafts, up to 70 Nm



BZY  
Cylindrical elastomount, Steel



RFK48B  
Hypoid gearbox - Stainless steel, up to 48 Nm



RTN  
BoWex® curved tooth coupling, Nylon



WJRM  
Drylin® W hybrid bearing block, Hybrid



G-ECO  
Eco range Spur gear, Steel C45

## Complementary products



PRF4545  
Standard aluminium profile, 45 x 45 mm