

T-Clip - Aluminium profile attachment

TCL

- A T-Clip comprises one insert and one key

- Resistance:

Tear strength: 9Kg

To slipping: 5kg


Advantages

- Allows components to be instantly mounted on an aluminium profile without the need of any tools.
- There are many standard accessories available but any component into which a 15mm diameter hole can be drilled to receive the T-Clip, may also be attached.



Info.

- Not sold individually, please contact us for details

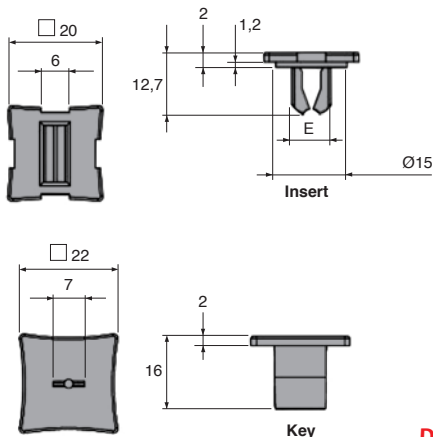

DISCOUNTS

Qty	1+	20+	50+
Disc.	List	-5%	On request

Part number	Weight (g)	For slot width	E	Stock*	Price each 1 to 19
TCL-8	2,8	8	8	4	1,01 €
TCL-10	3,1	10	10	4	1,04 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

227

Our other products



SLH-M
Toggle clamp, Round ended nut for SLH/SLV clamp



REGP
Aluminium ruler, With fixing holes



BPLF
Ball transfer unit, Light



PRF4545_P
Strippable aluminium profile, 45 x 45 mm



ZHG8
Spur gear, Machined plastic (delrin)



RPCtc
Wheel pivoting with central hole, Steel - Polyamide - with double brake



FDS
Flexible drive shaft, Masterflex® Steel, with PVC casing



CHN_CHNSS
Straight long link chain, Stainless steel



GLB
Small 6 lobe threaded handle, Technopolymer -



GE
Flexible toggle latch, Standard



BPPE
Ball transfer unit, Light



BAC105
Storage bin, 8mm

Complementary products



TCL-PD
T-Clip - Aluminium profile attachment, Document holder



TCL-PD
T-Clip - Aluminium profile attachment, Cable support



TCL-CR
T-Clip - Aluminium profile attachment, Hook



TCL-CR
T-Clip - Aluminium profile attachment, Magnetic object holder