

# T-Clip - Aluminium profile attachment

TCL

- A T-Clip comprises one insert and one key

- Resistance:  
Tear strength: 9Kg  
To slipping: 5kg


## Advantages

- Allows components to be instantly mounted on an aluminium profile without the need of any tools.
- There are many standard accessories available but any component into which a 15mm diameter hole can be drilled to receive the T-Clip, may also be attached.



## Info.

- Not sold individually, please contact us for details

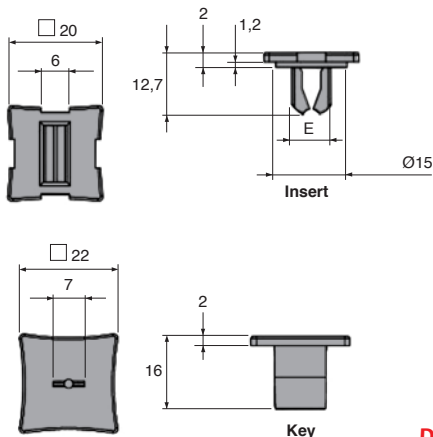

## DISCOUNTS

Qty	1+	20+	50+
Disc.	List	-5%	On request

Part number	Weight (g)	For slot width	E	Stock*	Price each 1 to 19
TCL-8	2,8	8	8	4	1,01 €
TCL-10	3,1	10	10	4	1,04 €

Dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

227

## Our other products



GG2

Ground spur gear,  
Heat treated steel



VMS

Stainless steel knurled  
thumb screw, Knurled




LC

Friction clutch, 190 to  
1800 Nm



BCFH

Mushroom headed  
button Hygienic  
Usit®, With male  
thread and high head

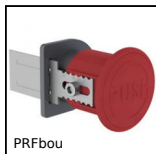

PRFbou

Emergency release  
button for aluminium  
profile, Emergency  
release bu...



RBNpl

Swivel castor with  
double brake, Steel -  
rubber



M2

Worm and wheel set,  
Unhardened steel



SHA

Handwheel without  
handle, Polyamide



LWH

High rigidity linear  
slide, Rail - from 9320  
N to 71300 N



FHCSS

Countersunk screw,  
Stainless steel A2 -  
DIN 7991



SLVVlok

Vertical toggle clamp,  
Vertical toggle clamp /  
vertical foot



TBD

Manual leadscrew  
table with opposing  
threads, 16mm guide  
rods

## Complementary products



TCL-PD

T-Clip - Aluminium  
profile attachment,  
Document holder



TCL-PD

T-Clip - Aluminium  
profile attachment,  
Cable support



TCL-CR

T-Clip - Aluminium  
profile attachment,  
Hook



TCL-CR

T-Clip - Aluminium  
profile attachment,  
Magnetic object  
holder