


- Suitable for mounting and positioning GTC belt rollers and PTR sprockets in a variety of positions
- Material:  
Plated XC38 steel  
304L stainless steel
- \*Anti-rotation system

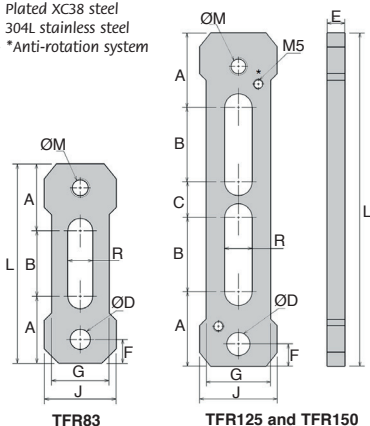


TFR83

TFR125 and TFR150



Typical application using GTC belt roller

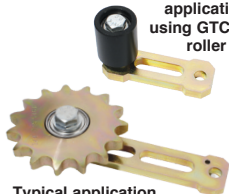

Typical application using PTR sprocket

### DISCOUNTS

Qty	1+	4+	10+
Disc.	List -10%	On request	

Part number	A	B	C	ØD	E	F	G	J	L	ØM	R	Stock*	Price each 1 to 3
<b>Steel version</b>													
TFR83-8	28	27,5	-	8,5	8	10	24	30	83,5	M8	10,5	✓	14,35 €
TFR83-10	28	27,5	-	8,5	8	10	24	30	83,5	M10	10,5	-	14,79 €
TFR125-8	28	27,5	14	10,5	8	10	24	30	125	M8	10,5	✓	15,35 €
TFR125-10	28	27,5	14	10,5	8	10	24	30	125	M10	10,5	✓	15,94 €
TFR125-12	28	27,5	14	10,5	8	10	24	30	125	M12	10,5	✓	16,81 €
TFR150-10	33,5	33,5	16	12,5	8	15	29	35	150	M10	12,5	-	24,07 €
TFR150-12	33,5	33,5	16	12,5	8	15	29	35	150	M12	12,5	✓	24,66 €
TFR150-16	33,5	33,5	16	12,5	8	15	29	35	150	M16	12,5	-	25,52 €
<b>Stainless steel version</b>													
TFR83-8/SS	28	27,5	-	8,5	8	10	24	30	83,5	M8	10,5	-	22,62 €
TFR83-10/SS	28	27,5	-	8,5	8	10	24	30	83,5	M10	10,5	-	23,50 €
TFR125-8/SS	28	27,5	14	10,5	8	10	24	30	125	M8	10,5	-	28,44 €
TFR125-10/SS	28	27,5	14	10,5	8	10	24	30	125	M10	10,5	-	29,30 €
TFR125-12/SS	28	27,5	14	10,5	8	10	24	30	125	M12	10,5	-	31,34 €
TFR150-10/SS	33,5	33,5	16	12,5	8	15	29	35	150	M10	12,5	-	43,83 €
TFR150-12/SS	33,5	33,5	16	12,5	8	15	29	35	150	M12	12,5	-	44,42 €
TFR150-16/SS	33,5	33,5	16	12,5	8	15	29	35	150	M16	12,5	-	45,87 €

\*Depending on availability - Dimensions in mm

## Our other products



SVT20

Screwjack with travelling screw, with translating screw



EFSM

Igubal® flange bearing, Polymer



EMS

Stainless steel knurled thumb nut, Knurled



BCM\_T

Driving collar, Driving collar



HK

Manual locking clamp, Manual locking clamp LRX



PSG15

Spur gear - precision range, Pre-hardened Steel 35NCD6



BOXKK

Boxed set of DIN6885A keys, Boxed set - Steel or stainless steel



 
HSSss

Stainless steel shoulder screw ISO7379, Stainless steel ISO 7379



PRFRTR

Cross connector for aluminium profile,




LAT4

4A motorised linear actuator, 4 amperes



GE32

Sprung toggle latch with connecting link,

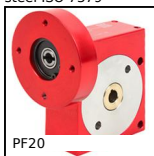

PF20

Worm and wheel gear reducer, up to 5 Nm

## Complementary products



GTCSS

Belt tensioner, For use in hostile environments



PTRSS

Idler chain sprocket, For hostile environments