

- Suitable for mounting and positioning GTC belt rollers and PTR sprockets

- Material:

Plated XC38 steel

304L stainless steel

steel or stainless steel

Accessories

- GTC belt tensioner (tome 4 p.146)


- PTR idler chain sprocket (tome 4 p.140)



Typical application using GTC belt roller



Typical application using PTR sprocket

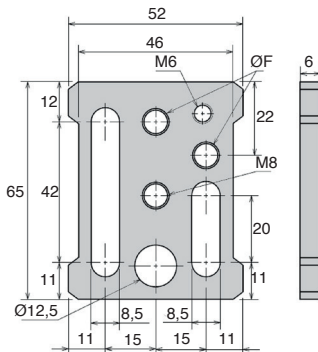

DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-10%	On request

Part number	Material	ØF	Stock*	Price each 1 to 3
TMR-8	Steel	M8	✓	25,97 €
TMR-10	Steel	M10	-	25,97 €
TMR-8/SS	Stainless steel	M8	-	33,44 €
TMR-10/SS	Stainless steel	M10	-	33,44 €



*Depending on availability - Dimensions in mm

- Suitable for mounting and positioning GTC belt rollers and PTR sprockets in a variety of positions
- Material:
Plated XC38 steel
304L stainless steel
- *Anti-rotation system



Accessories

- GTC belt tensioner (tome 4 p.146)
- PTR idler chain sprocket (tome 4 p.140)

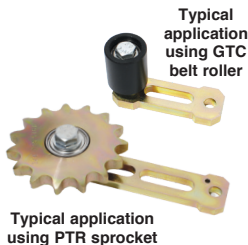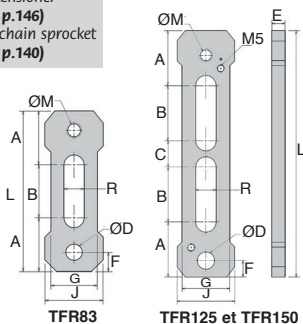

DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-10%	On request

Part number	A	B	C	ØD	E	F	G	J	L	ØM	R	Price each 1 to 3
Steel version												
TFR83-8	28	27,5	-	8,5	8	10	24	30	83,5	M8	10,5	✓ 14,77 €
TFR83-10	28	27,5	-	8,5	8	10	24	30	83,5	M10	10,5	- 15,22 €
TFR125-8	28	27,5	14	10,5	8	10	24	30	125	M8	10,5	✓ 15,80 €
TFR125-10	28	27,5	14	10,5	8	10	24	30	125	M10	10,5	✓ 16,40 €
TFR125-12	28	27,5	14	10,5	8	10	24	30	125	M12	10,5	✓ 17,30 €
TFR150-12	33,5	33,5	16	12,5	8	15	29	35	150	M12	12,5	✓ 25,38 €
TFR150-16	33,5	33,5	16	12,5	8	15	29	35	150	M16	12,5	- 26,27 €
Stainless steel version												
TFR83-8/SS	28	27,5	-	8,5	8	10	24	30	83,5	M8	10,5	- 23,28 €
TFR83-10/SS	28	27,5	-	8,5	8	10	24	30	83,5	M10	10,5	- 24,19 €
TFR125-8/SS	28	27,5	14	10,5	8	10	24	30	125	M8	10,5	- 29,28 €
TFR125-10/SS	28	27,5	14	10,5	8	10	24	30	125	M10	10,5	- 30,15 €
TFR125-12/SS	28	27,5	14	10,5	8	10	24	30	125	M12	10,5	- 32,26 €
TFR150-10/SS	33,5	33,5	16	12,5	8	15	29	35	150	M10	12,5	- 45,11 €
TFR150-12/SS	33,5	33,5	16	12,5	8	15	29	35	150	M12	12,5	- 45,72 €
TFR150-16/SS	33,5	33,5	16	12,5	8	15	29	35	150	M16	12,5	- 47,21 €

* Depending on availability - Dimensions in mm

Our other products



 
Adjusting rod for clamp - Female, Bored



Steel spur gear, Steel 20NCD2



90° ball and socket joints DIN71802, Steel



Strike for toggle latch, 20mm



Stainless steel Clamping collar, Stainless steel



Single stainless steel universal joint, Low duty



Strike for toggle latch, 25.5mm



Stainless steel flexible bellows coupling, Stainless steel - with se...



Spring loaded latch, Spring return latch -



HTD Heavy duty timing pulley, HTD8



Accessories, Clamping lever

 


Wormwheel, Bronze


Complementary products



Belt tensioner, For standard applications



 Idler chain sprocket, For standard applications



Idler chain sprocket, For standard applications