


- Suitable for mounting and positioning GTC belt rollers and PTR sprockets in a variety of positions
- Material:
Plated XC38 steel
304L stainless steel
- *Anti-rotation system

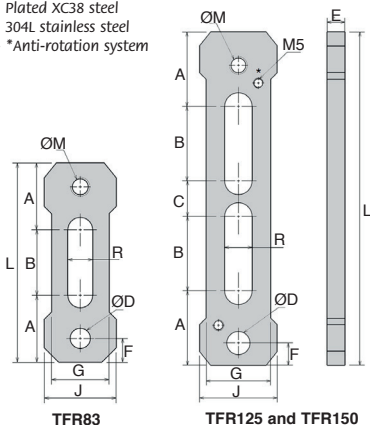


TFR83

TFR125 and TFR150



Typical application using GTC belt roller

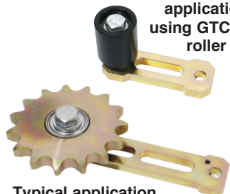

Typical application using PTR sprocket

DISCOUNTS

Qty	1+	4+	10+
Disc.	List -10%	On request	On request

Part number	A	B	C	ØD	E	F	G	J	L	ØM	R	Stock*	Price each 1 to 3
Steel version													
TFR83-8	28	27,5	-	8,5	8	10	24	30	83,5	M8	10,5	✓	14,35 €
TFR83-10	28	27,5	-	8,5	8	10	24	30	83,5	M10	10,5	-	14,79 €
TFR125-8	28	27,5	14	10,5	8	10	24	30	125	M8	10,5	✓	15,35 €
TFR125-10	28	27,5	14	10,5	8	10	24	30	125	M10	10,5	✓	15,94 €
TFR125-12	28	27,5	14	10,5	8	10	24	30	125	M12	10,5	✓	16,81 €
TFR150-10	33,5	33,5	16	12,5	8	15	29	35	150	M10	12,5	-	24,07 €
TFR150-12	33,5	33,5	16	12,5	8	15	29	35	150	M12	12,5	✓	24,66 €
TFR150-16	33,5	33,5	16	12,5	8	15	29	35	150	M16	12,5	-	25,52 €
Stainless steel version													
TFR83-8/SS	28	27,5	-	8,5	8	10	24	30	83,5	M8	10,5	-	22,62 €
TFR83-10/SS	28	27,5	-	8,5	8	10	24	30	83,5	M10	10,5	-	23,50 €
TFR125-8/SS	28	27,5	14	10,5	8	10	24	30	125	M8	10,5	-	28,44 €
TFR125-10/SS	28	27,5	14	10,5	8	10	24	30	125	M10	10,5	-	29,30 €
TFR125-12/SS	28	27,5	14	10,5	8	10	24	30	125	M12	10,5	-	31,34 €
TFR150-10/SS	33,5	33,5	16	12,5	8	15	29	35	150	M10	12,5	-	43,83 €
TFR150-12/SS	33,5	33,5	16	12,5	8	15	29	35	150	M12	12,5	-	44,42 €
TFR150-16/SS	33,5	33,5	16	12,5	8	15	29	35	150	M16	12,5	-	45,87 €

*Depending on availability - Dimensions in mm

Our other products




MAX26

Motor-gearbox 12V and 24V DC, from 0,075 to 0,6Nm



LVT

Miniature motorised actuator 2A, 2 ampers

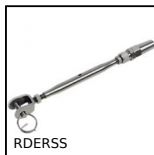

RDERSS

Stainless steel manual rigging screw, Stainless steel - manual



ACLEFS

Floor anchor for aluminium profile, Adjustable



CHAR

Spring hinge, screwed



NT91

Spur gear coaxial gearbox, from 10 to 35 Nm - In-line



PCF2

Conical flexible mount, Oval base plate



PW_PWG15

Worm - precision range, Steel



ACLBT5

Closing system for aluminium profile, Spacer for spherical ended stop



CHTRP

Single and dual output gearboxes, Up to 28,8 Nm



RFVfp

Stainless steel worm and wheel gearboxes, Mounting bracket



DOMI50

Domino 50 adjustable slide, Slide DOMILINE 50 with counter and handw...

Complementary products



GTCSS

Belt tensioner, For use in hostile environments



PTRSS

Idler chain sprocket, For hostile environments