


- Suitable for mounting and positioning GTC belt rollers and PTR sprockets in a variety of positions
- Material:  
Plated XC38 steel  
304L stainless steel
- \*Anti-rotation system

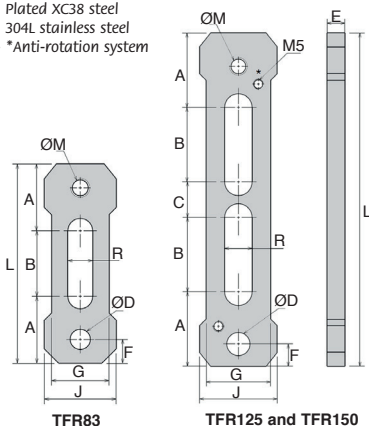


TFR83

TFR125 and TFR150



Typical application using GTC belt roller

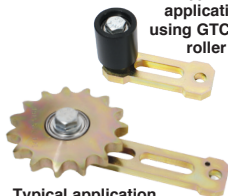

Typical application using PTR sprocket

### DISCOUNTS

Qty	1+	4+	10+
Disc.	List -10%	On request	On request

Part number	A	B	C	ØD	E	F	G	J	L	ØM	R	Stock*	Price each 1 to 3
<b>Steel version</b>													
TFR83-8	28	27,5	-	8,5	8	10	24	30	83,5	M8	10,5	✓	14,35 €
TFR83-10	28	27,5	-	8,5	8	10	24	30	83,5	M10	10,5	-	14,79 €
TFR125-8	28	27,5	14	10,5	8	10	24	30	125	M8	10,5	✓	15,35 €
TFR125-10	28	27,5	14	10,5	8	10	24	30	125	M10	10,5	✓	15,94 €
TFR125-12	28	27,5	14	10,5	8	10	24	30	125	M12	10,5	✓	16,81 €
TFR150-10	33,5	33,5	16	12,5	8	15	29	35	150	M10	12,5	-	24,07 €
TFR150-12	33,5	33,5	16	12,5	8	15	29	35	150	M12	12,5	✓	24,66 €
TFR150-16	33,5	33,5	16	12,5	8	15	29	35	150	M16	12,5	-	25,52 €
<b>Stainless steel version</b>													
TFR83-8/SS	28	27,5	-	8,5	8	10	24	30	83,5	M8	10,5	-	22,62 €
TFR83-10/SS	28	27,5	-	8,5	8	10	24	30	83,5	M10	10,5	-	23,50 €
TFR125-8/SS	28	27,5	14	10,5	8	10	24	30	125	M8	10,5	-	28,44 €
TFR125-10/SS	28	27,5	14	10,5	8	10	24	30	125	M10	10,5	-	29,30 €
TFR125-12/SS	28	27,5	14	10,5	8	10	24	30	125	M12	10,5	-	31,34 €
TFR150-10/SS	33,5	33,5	16	12,5	8	15	29	35	150	M10	12,5	-	43,83 €
TFR150-12/SS	33,5	33,5	16	12,5	8	15	29	35	150	M12	12,5	-	44,42 €
TFR150-16/SS	33,5	33,5	16	12,5	8	15	29	35	150	M16	12,5	-	45,87 €

\*Depending on availability - Dimensions in mm

## Our other products



HRV

V- rail guidance  
Simple Select®  
system, Rail with  
carriage



TFR

Rigid manual  
tensioner, Fixed



ACL

Joints for aluminium  
profile, Variable angle  
hinge



CHA60

Rectangular hinge,  
drilled or countersunk,  
Rectangular, drilled or  
C...



SLHVlok

Horizontal toggle  
clamp, Horizontal  
toggle clamp / vertical  
foot



PSG05S

Spur gear - precision  
range, Stainless steel  
303



YG1

HEAVY DUTY spur  
gear, Steel 35NCD6



PRF1945

Standard aluminium  
profile, 19 x 45 mm



 
MET

Cylindrical sintered  
bronze bush, Self-



PCatherm

Pull handle,  
Thermoplastic



H0

Crossed helical gear  
crossed axis at 90°,



MRAeco

Low cost quick link,  
Steel

## Complementary products



 
GTC

Belt tensioner, For  
standard applications



PTR

Idler chain sprocket,  
For standard  
applications



PTR

Idler chain sprocket,  
For standard  
applications