

- Suitable for mounting and positioning GTC belt rollers and PTR sprockets

- Material:

Plated XC38 steel

304L stainless steel

steel or stainless steel

### Accessories

- GTC belt tensioner (tome 4 p.146)


- PTR idler chain sprocket (tome 4 p.140)



Typical application using GTC belt roller



Typical application using PTR sprocket

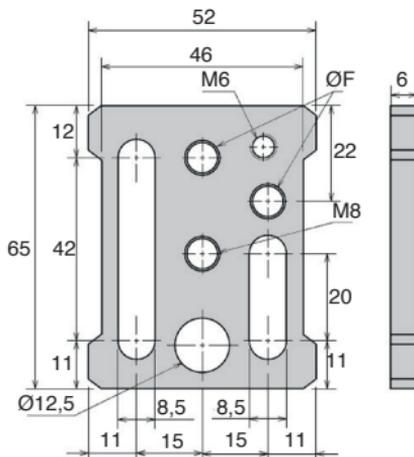

### DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-10%	On request

Part number	Material	ØF	Stock*	Price each 1 to 3
TMR-8	Steel	M8	✓	25,97 €
TMR-10	Steel	M10	-	25,97 €
TMR-8/SS	Stainless steel	M8	-	33,44 €
TMR-10/SS	Stainless steel	M10	-	33,44 €



\*Depending on availability - Dimensions in mm

- Suitable for mounting and positioning GTC belt rollers and PTR sprockets in a variety of positions
- Material:  
Plated XC38 steel  
304L stainless steel
- \*Anti-rotation system



### Accessories

- GTC belt tensioner (tome 4 p.146)
- PTR idler chain sprocket (tome 4 p.140)

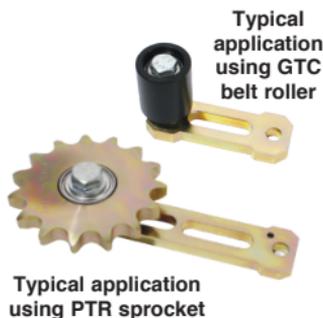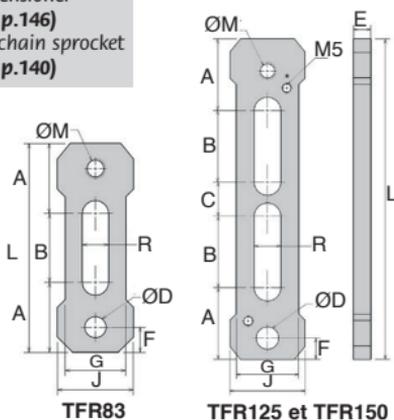

### DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-10%	On request

Part number	A	B	C	ØD	E	F	G	J	L	ØM	R	Price each 1 to 3
<b>Steel version</b>												
TFR83-8	28	27,5	-	8,5	8	10	24	30	83,5	M8	10,5	✓ 14,77 €
TFR83-10	28	27,5	-	8,5	8	10	24	30	83,5	M10	10,5	- 15,22 €
TFR125-8	28	27,5	14	10,5	8	10	24	30	125	M8	10,5	✓ 15,80 €
TFR125-10	28	27,5	14	10,5	8	10	24	30	125	M10	10,5	✓ 16,40 €
TFR125-12	28	27,5	14	10,5	8	10	24	30	125	M12	10,5	✓ 17,30 €
TFR150-12	33,5	33,5	16	12,5	8	15	29	35	150	M12	12,5	✓ 25,38 €
TFR150-16	33,5	33,5	16	12,5	8	15	29	35	150	M16	12,5	- 26,27 €
<b>Stainless steel version</b>												
TFR83-8/SS	28	27,5	-	8,5	8	10	24	30	83,5	M8	10,5	- 23,28 €
TFR83-10/SS	28	27,5	-	8,5	8	10	24	30	83,5	M10	10,5	- 24,19 €
TFR125-8/SS	28	27,5	14	10,5	8	10	24	30	125	M8	10,5	- 29,28 €
TFR125-10/SS	28	27,5	14	10,5	8	10	24	30	125	M10	10,5	- 30,15 €
TFR125-12/SS	28	27,5	14	10,5	8	10	24	30	125	M12	10,5	- 32,26 €
TFR150-10/SS	33,5	33,5	16	12,5	8	15	29	35	150	M10	12,5	- 45,11 €
TFR150-12/SS	33,5	33,5	16	12,5	8	15	29	35	150	M12	12,5	- 45,72 €
TFR150-16/SS	33,5	33,5	16	12,5	8	15	29	35	150	M16	12,5	- 47,21 €

\* Depending on availability - Dimensions in mm

## Our other products



**BABFCFO**  
Ball pin socket,  
Mounting collar with a  
round flange



**DILC**  
Indexing plunger with  
cam, with cam



**SUP**  
Self-centering  
clamping hub steel,  
Without locknut



**KB\_OP**  
Open precision linear  
bearing, Precision -  
steel



**R203**  
Die spring ISO10243,  
Light




**AC**  
Strike for toggle latch,  
20mm



**OP3**  
Mechanical digital  
position indicator, 4  
numbers



**ESCON**  
Speed controller 5A, 5  
A

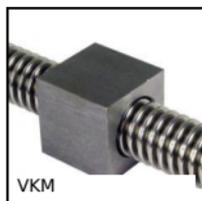

**VKM**  
Square steel nut,  
Steel - 1 thread



**LSAG**  
Precision linear rotary  
ball spline, Rail - from  
514 N to 15386 N



**MHXred**  
Reducing sleeve  
male/female,  
Hexagonal - stainless  
steel



**COA-COG**  
Surface mounting  
plate, Surface  
mounting plate for  
clevis

## Complementary products



**GTCSS**  
Belt tensioner, For use  
in hostile  
environments



**PTRSS**  
Idler chain sprocket,  
For hostile  
environments