


- Suitable for mounting and positioning GTC belt rollers and PTR sprockets in a variety of positions
- Material:
Plated XC38 steel
304L stainless steel
- *Anti-rotation system

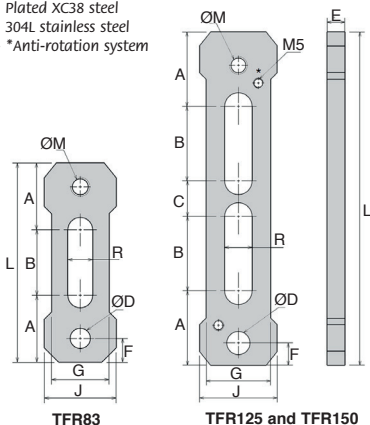


TFR83

TFR125 and TFR150



Typical application using GTC belt roller

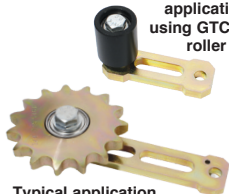

Typical application using PTR sprocket

DISCOUNTS

Qty	1+	4+	10+
Disc.	List -10%	On request	

Part number	A	B	C	ØD	E	F	G	J	L	ØM	R	Stock*	Price each 1 to 3
Steel version													
TFR83-8	28	27,5	-	8,5	8	10	24	30	83,5	M8	10,5	✓	14,35 €
TFR83-10	28	27,5	-	8,5	8	10	24	30	83,5	M10	10,5	-	14,79 €
TFR125-8	28	27,5	14	10,5	8	10	24	30	125	M8	10,5	✓	15,35 €
TFR125-10	28	27,5	14	10,5	8	10	24	30	125	M10	10,5	✓	15,94 €
TFR125-12	28	27,5	14	10,5	8	10	24	30	125	M12	10,5	✓	16,81 €
TFR150-10	33,5	33,5	16	12,5	8	15	29	35	150	M10	12,5	-	24,07 €
TFR150-12	33,5	33,5	16	12,5	8	15	29	35	150	M12	12,5	✓	24,66 €
TFR150-16	33,5	33,5	16	12,5	8	15	29	35	150	M16	12,5	-	25,52 €
Stainless steel version													
TFR83-8/SS	28	27,5	-	8,5	8	10	24	30	83,5	M8	10,5	-	22,62 €
TFR83-10/SS	28	27,5	-	8,5	8	10	24	30	83,5	M10	10,5	-	23,50 €
TFR125-8/SS	28	27,5	14	10,5	8	10	24	30	125	M8	10,5	-	28,44 €
TFR125-10/SS	28	27,5	14	10,5	8	10	24	30	125	M10	10,5	-	29,30 €
TFR125-12/SS	28	27,5	14	10,5	8	10	24	30	125	M12	10,5	-	31,34 €
TFR150-10/SS	33,5	33,5	16	12,5	8	15	29	35	150	M10	12,5	-	43,83 €
TFR150-12/SS	33,5	33,5	16	12,5	8	15	29	35	150	M12	12,5	-	44,42 €
TFR150-16/SS	33,5	33,5	16	12,5	8	15	29	35	150	M16	12,5	-	45,87 €

*Depending on availability - Dimensions in mm

Our other products



MET
Cylindrical sintered bronze bush, Self-lubricating sintered bronze



IN1
Internal gear, Steel 20NCD2



WJUM20
Drylin® W bearing block, Slide



GE
Toggle latches, Standard




GMK17_BR
Clamp for guiding profile, Rounded only - single



SRP
Slotted spring pin ISO8752, Split ISO 8752




PM4
Worm and wheel set, Bronze

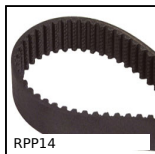

RPP14
RPP heavy duty timing belt, RPP14



 BAG-MI
Split shaft collar with clamp lever, Steel



H1
Crossed helical gear crossed axis at 90°



HAR9
Captive C washer, DIN 6371



PLA
Flat magnet, Flat magnet

Complementary products



GTCSS
Belt tensioner, For use in hostile environments



PTRSS
Idler chain sprocket, For hostile environments