

- **Conforms to DIN 975**
- **Material:**  
Stainless steel: 303/304 - A2
- **Working temperature up to +430°C**

### Uses


- Suitable for harsh environments

### Options

- Stainless steel 316

### Accessories

- Nuts **SHN**
- Stainless steel screws

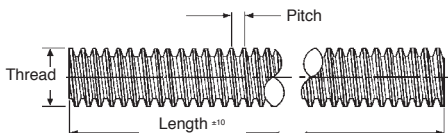

### DISCOUNTS

|              |      |      |      |            |
|--------------|------|------|------|------------|
| <b>Qty</b>   | 1+   | 6+   | 20+  | 40+        |
| <b>Disc.</b> | List | -15% | -20% | On request |


| Part number | Thread | Pitch | Length (mm) | Stock* | Price each 1 to 5 |
|-------------|--------|-------|-------------|--------|-------------------|
| TIF-2/SS    | M2     | 0,40  | 1000        | ✓      | 10,11 €           |
| TIF-2.5/SS  | M2,5   | 0,45  | 1000        | ✓      | 11,08 €           |
| TIF-3/SS    | M3     | 0,50  | 1000        | ✓      | 4,02 €            |
| TIF-4/SS    | M4     | 0,70  | 1000        | ✓      | 4,00 €            |
| TIF-5/SS    | M5     | 0,80  | 1000        | ✓      | 2,76 €            |
| TIF-6/SS    | M6     | 1,00  | 1000        | ✓      | 3,05 €            |
| TIF-8/SS    | M8     | 1,25  | 1000        | ✓      | 5,74 €            |
| TIF-10/SS   | M10    | 1,50  | 1000        | ✓      | 9,22 €            |
| TIF-12/SS   | M12    | 1,75  | 1000        | ✓      | 13,34 €           |
| TIF-14/SS   | M14    | 2,00  | 1000        | ✓      | 18,34 €           |
| TIF-16/SS   | M16    | 2,00  | 1000        | ✓      | 22,29 €           |
| TIF-18/SS   | M18    | 2,50  | 1000        | ✓      | 32,60 €           |
| TIF-20/SS   | M20    | 2,50  | 1000        | ✓      | 36,31 €           |
| TIF-22/SS   | M22    | 2,50  | 1000        | -      | 48,21 €           |
| TIF-24/SS   | M24    | 3,00  | 1000        | -      | 51,99 €           |
| TIF-27/SS   | M27    | 3,00  | 1000        | -      | 79,03 €           |
| TIF-30/SS   | M30    | 3,50  | 1000        | -      | 99,95 €           |
| TIF-33/SS   | M33    | 3,50  | 1000        | -      | 118,04 €          |
| TIF-36/SS   | M36    | 4,00  | 1000        | -      | 135,07 €          |

\*Depending on availability - Dimensions in mm

## Our other products



 HLC24  
Right angle spiro bevel gearbox, Up to 78Nm



BLHM30  
Right angled gearbox, double output shafts, up to 4.4 Nm



CHA225  
Screwed hinge with threaded insert, 225 degrees



MHSC  
Single-disc flexible coupling, Single disk



CHAU  
Screwed hinge, 270°



CLAT  
Clamping lever Hygienic Usit® - male, Stainless steel



PTA150  
Articulated levelling foot, pressed base Ø150, Ø 150



EBM  
Steel U bolt, Steel



H02  
Single needle roller universal joint, Heavy duty



PGT  
Sliding profile, Sliding panel support



PSG1  
Spur gear - precision range, Case hardened steel 20NCD2



RPCtcss  
Swivel castor with central hole, Stainless steel - Polyamide

## Complementary products



SHN  
Hexagonal nut DIN934, A2 Stainless steel



SHW  
Plain washer, A2 Stainless steel



MCL  
Cylindrical threaded sleeve, Cylindrical - stainless steel



MHX  
Hexagonal threaded sleeve, Hexagonal - stainless steel