

- **Conforms to DIN 975**
- **Material:**
Stainless steel: 303/304 - A2
- **Working temperature up to +430°C**

Uses


- Suitable for harsh environments

Options

- Stainless steel 316

Accessories

- Nuts **SHN**
- Stainless steel screws

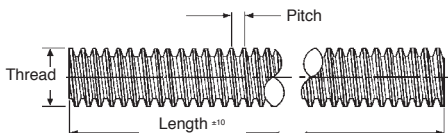

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	Thread	Pitch	Length (mm)	Stock*	Price each 1 to 5
TIF-2/SS	M2	0,40	1000	✓	10,11 €
TIF-2.5/SS	M2,5	0,45	1000	✓	11,08 €
TIF-3/SS	M3	0,50	1000	✓	4,02 €
TIF-4/SS	M4	0,70	1000	✓	4,00 €
TIF-5/SS	M5	0,80	1000	✓	2,76 €
TIF-6/SS	M6	1,00	1000	✓	3,05 €
TIF-8/SS	M8	1,25	1000	✓	5,74 €
TIF-10/SS	M10	1,50	1000	✓	9,22 €
TIF-12/SS	M12	1,75	1000	✓	13,34 €
TIF-14/SS	M14	2,00	1000	✓	18,34 €
TIF-16/SS	M16	2,00	1000	✓	22,29 €
TIF-18/SS	M18	2,50	1000	✓	32,60 €
TIF-20/SS	M20	2,50	1000	✓	36,31 €
TIF-22/SS	M22	2,50	1000	-	48,21 €
TIF-24/SS	M24	3,00	1000	-	51,99 €
TIF-27/SS	M27	3,00	1000	-	79,03 €
TIF-30/SS	M30	3,50	1000	-	99,95 €
TIF-33/SS	M33	3,50	1000	-	118,04 €
TIF-36/SS	M36	4,00	1000	-	135,07 €

*Depending on availability - Dimensions in mm

 
Our other products



Half-rail guide, Rail



Right angle spiro bevel gearbox, Up to 43Nm



RPP heavy duty timing belt, RPP3



Wheel, Grey rubber - Polypropylene rim



Small 6 lobe female handle, Technopolymer - Stainless steel



Speed controller 5A, 5 A



Flat magnet, Flat magnet with threaded hole



Mounting sleeve for lock pin, Nickel-plated steel or Stainless steel



Idle chain sprocket, For hostile environments



T type timing pulley, Economy range - T10 aluminium



Right angled gearbox, from 0.20 to 2 Nm



Hinge for aluminium profile, Surface mounting hinge

Complementary products



Hexagonal nut DIN934, A2 Stainless steel



Plain washer, A2 Stainless steel



Cylindrical threaded sleeve, Cylindrical - stainless steel



Hexagonal threaded sleeve, Hexagonal - stainless steel