

- **Conforms to DIN 975**
- **Material:**  
Stainless steel: 303/304 - A2
- **Working temperature up to +430°C**

### Uses


- Suitable for harsh environments

### Options

- Stainless steel 316

### Accessories

- Nuts **SHN**
- Stainless steel screws

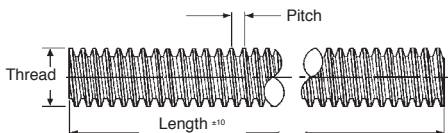

### DISCOUNTS

<b>Qty</b>	1+	6+	20+	40+
<b>Disc.</b>	List	-15%	-20%	On request

Part number	Thread	Pitch	Length (mm)	Stock*	Price each 1 to 5
TIF-2/SS	M2	0,40	1000	✓	10,11 €
TIF-2.5/SS	M2,5	0,45	1000	✓	11,08 €
TIF-3/SS	M3	0,50	1000	✓	4,02 €
TIF-4/SS	M4	0,70	1000	✓	4,00 €
TIF-5/SS	M5	0,80	1000	✓	2,76 €
TIF-6/SS	M6	1,00	1000	✓	3,05 €
TIF-8/SS	M8	1,25	1000	✓	5,74 €
TIF-10/SS	M10	1,50	1000	✓	9,22 €
TIF-12/SS	M12	1,75	1000	✓	13,34 €
TIF-14/SS	M14	2,00	1000	✓	18,34 €
TIF-16/SS	M16	2,00	1000	✓	22,29 €
TIF-18/SS	M18	2,50	1000	✓	32,60 €
TIF-20/SS	M20	2,50	1000	✓	36,31 €
TIF-22/SS	M22	2,50	1000	-	48,21 €
TIF-24/SS	M24	3,00	1000	-	51,99 €
TIF-27/SS	M27	3,00	1000	-	79,03 €
TIF-30/SS	M30	3,50	1000	-	99,95 €
TIF-33/SS	M33	3,50	1000	-	118,04 €
TIF-36/SS	M36	4,00	1000	-	135,07 €

\*Depending on availability - Dimensions in mm

## Our other products



 
Hexagonal shaft,  
Hexagonal shaft



Stainless steel wire  
thimble, Stainless  
steel



Elastic ringed latch,  
Hooks into a slot



Strike for toggle latch,  
20mm



Dylin® W rail, Rail




Conical flexible  
mount, Oval base  
plate



Hinge for aluminium  
profile, Hinge



 Domino 120  
adjustable slide, Slide  
DOMILINE 120



Worm and wheel set,  
Machined plastic



Arm with rotating  
handle, Square bore



Friction clutch, 30 to  
240 Nm



Miniature friction  
hinge, Friction

## Complementary products



Hexagonal nut  
DIN934, A2 Stainless  
steel



Plain washer, A2  
Stainless steel



Cylindrical threaded  
sleeve, Cylindrical -  
stainless steel



Hexagonal threaded  
sleeve, Hexagonal -  
stainless steel