

- **Conforms to DIN 975**
- **Material:**  
Stainless steel: 303/304 - A2
- **Working temperature up to +430°C**

### Uses


- Suitable for harsh environments

### Options

- Stainless steel 316

### Accessories

- Nuts **SHN**
- Stainless steel screws

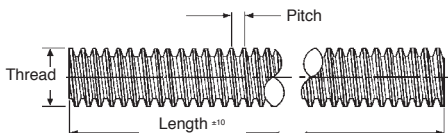

### DISCOUNTS

<b>Qty</b>	1+	6+	20+	40+
<b>Disc.</b>	List	-15%	-20%	On request

Part number	Thread	Pitch	Length (mm)	Stock*	Price each 1 to 5
TIF-2/SS	M2	0,40	1000	✓	10,11 €
TIF-2.5/SS	M2,5	0,45	1000	✓	11,08 €
TIF-3/SS	M3	0,50	1000	✓	4,02 €
TIF-4/SS	M4	0,70	1000	✓	4,00 €
TIF-5/SS	M5	0,80	1000	✓	2,76 €
TIF-6/SS	M6	1,00	1000	✓	3,05 €
TIF-8/SS	M8	1,25	1000	✓	5,74 €
TIF-10/SS	M10	1,50	1000	✓	9,22 €
TIF-12/SS	M12	1,75	1000	✓	13,34 €
TIF-14/SS	M14	2,00	1000	✓	18,34 €
TIF-16/SS	M16	2,00	1000	✓	22,29 €
TIF-18/SS	M18	2,50	1000	✓	32,60 €
TIF-20/SS	M20	2,50	1000	✓	36,31 €
TIF-22/SS	M22	2,50	1000	-	48,21 €
TIF-24/SS	M24	3,00	1000	-	51,99 €
TIF-27/SS	M27	3,00	1000	-	79,03 €
TIF-30/SS	M30	3,50	1000	-	99,95 €
TIF-33/SS	M33	3,50	1000	-	118,04 €
TIF-36/SS	M36	4,00	1000	-	135,07 €

\*Depending on availability - Dimensions in mm

## Our other products



Stainless steel spur gear, Stainless steel 304L



Mechanical speed variator, from 0,18 to 1,5kW



Adjustable Stainless steel cam lever, Male



Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm



Joints for aluminium profile, Variable angle hinge



Pin for magnetic bush, Fast and light magnetic locking



Horizontal hook toggle clamp, Horizontal Hook clamp - steel



Magnetic stop for aluminium profile, Magnetic stop




Chain sprocket with hardened teeth,



Magnetic head screw, With rubber coating



Flat magnet, Flat magnet with threaded

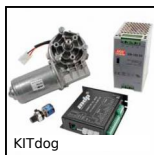

24V DC motorisation kit, Worm and wheel

## Complementary products



Hexagonal nut DIN934, A2 Stainless steel



Plain washer, A2 Stainless steel



Cylindrical threaded sleeve, Cylindrical - stainless steel



Hexagonal threaded sleeve, Hexagonal - stainless steel