

# Threaded stud **DIN 976A**




## TIF

## Steel

### - Short threaded stud

#### - Material:

Galvanised steel, class 4.6

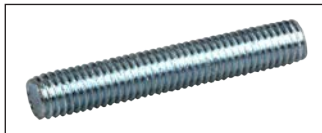


### Info.

- Other lengths available on request

### Accessories

- SHN nuts

 - MCL and MHX sleeves



### DISCOUNTS

Qty	1+	5+	15+
Disc.	List	-5%	On request

Part number	ØF	L	Quantity per pack	Price each 1 to 4
TIF6-30/B	M6	30	200	21,09 €
TIF6-40/B	M6	40	200	25,38 €
TIF6-50/B	M6	50	200	28,85 €
TIF6-60/B	M6	60	200	37,47 €
TIF6-70/B	M6	70	200	40,93 €
TIF6-80/B	M6	80	200	43,54 €
TIF6-100/B	M6	100	200	53,90 €
TIF6-120/B	M6	120	200	62,53 €
TIF8-30/B	M8	30	200	28,85 €
TIF8-40/B	M8	40	200	34,91 €
TIF8-50/B	M8	50	200	39,19 €
TIF8-60/B	M8	60	200	47,83 €
TIF8-70/B	M8	70	200	52,18 €
TIF8-80/B	M8	80	200	57,35 €
TIF8-100/B	M8	100	200	66,00 €
TIF8-120/B	M8	120	200	87,55 €
TIF8-140/B	M8	140	200	110,88 €
TIF10-30/B	M10	30	100	23,04 €
TIF10-40/B	M10	40	100	25,21 €
TIF10-50/B	M10	50	100	27,80 €
TIF10-60/B	M10	60	100	33,00 €
TIF10-70/B	M10	70	100	40,30 €
TIF10-80/B	M10	80	100	43,34 €
TIF10-100/B	M10	100	100	52,83 €
TIF10-120/B	M10	120	100	70,09 €
TIF10-140/B	M10	140	100	79,59 €
TIF10-160/B	M10	160	100	90,82 €
TIF12-40/B	M12	40	100	32,12 €
TIF12-50/B	M12	50	100	38,16 €
TIF12-60/B	M12	60	100	45,48 €
TIF12-70/B	M12	70	100	53,70 €
TIF12-80/B	M12	80	100	63,21 €
TIF12-100/B	M12	100	100	74,43 €
TIF12-120/B	M12	120	100	100,31 €
TIF12-140/B	M12	140	100	115,41 €
TIF12-160/B	M12	160	100	132,26 €

Dimensions in mm

## Our other products



TB8

Cylindrical roller thrust bearing, Steel



SHTP

Drylin® Linear table, Economy range



T5M T10M

T type timing belt per metre, T5 Steel cored polyurethane



PRF\_PSA

Shaft support for aluminium profile, Linear guide shaft




RPCpl

Swivel castor with double brake, Steel - Polyamide



SH0

 Parallel axis helical gear, Steel 20NCD2



RPP14

RPP heavy duty timing belt, RPP14



TOC

Short swivel head, Short



GMK17\_BR

Clamp for guiding profile, Rounded only - single



PRES

Manual workbench press accessory for PRES-3HR end PRES-4HR, Set of s...



PW\_PWG15

Worm - precision range, Steel



PPG

Indexing plunger with flange, With horizontal mounting flange

## Complementary products



MHXred

Reducing sleeve male/female, Hexagonal - steel



SHW

Plain washer, Steel



MHX

Hexagonal threaded sleeve, Hexagonal - steel



MCL

Cylindrical threaded sleeve, Cylindrical - steel