

- **Conforms to DIN 975**
- **Material:**
Stainless steel: 303/304 - A2
- **Working temperature up to +430°C**

Uses


- Suitable for harsh environments

Options

- Stainless steel 316

Accessories

- Nuts **SHN** (tome 1 p.569)
- Stainless steel screws
- **MCL** and **MHX** sleeves (tome 1 p.524-528)

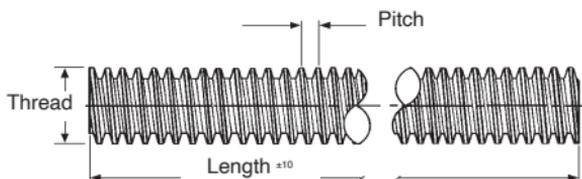

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	Thread	Pitch	Length (mm)	Stock*	Price each 1 to 5
TIF2-1000/SS	M2	0,40	1000	✓	11,26 €
TIF2.5-1000/SS	M2,5	0,45	1000	✓	12,35 €
TIF3-1000/SS	M3	0,50	1000	✓	6,70 €
TIF4-1000/SS	M4	0,70	1000	✓	4,44 €
TIF5-1000/SS	M5	0,80	1000	✓	3,06 €
TIF6-1000/SS	M6	1,00	1000	✓	3,38 €
TIF8-1000/SS	M8	1,25	1000	✓	6,40 €
TIF10-1000/SS	M10	1,50	1000	✓	10,26 €
TIF12-1000/SS	M12	1,75	1000	✓	14,86 €
TIF14-1000/SS	M14	2,00	1000	✓	20,44 €
TIF16-1000/SS	M16	2,00	1000	✓	24,85 €
TIF18-1000/SS	M18	2,50	1000	✓	36,37 €
TIF20-1000/SS	M20	2,50	1000	✓	40,50 €
TIF22-1000/SS	M22	2,50	1000	-	53,80 €
TIF24-1000/SS	M24	3,00	1000	-	57,99 €
TIF27-1000/SS	M27	3,00	1000	-	88,19 €
TIF30-1000/SS	M30	3,50	1000	-	111,53 €
TIF33-1000/SS	M33	3,50	1000	-	On request
TIF36-1000/SS	M36	4,00	1000	-	150,75 €

* Depending on availability - Dimensions in mm

Threaded stud **DIN 976A**




TIF

Steel

- Short threaded stud

- Material:

Galvanised steel, class 4.6

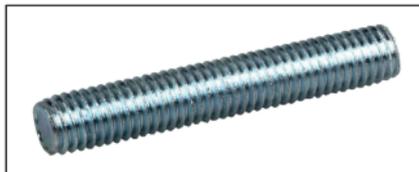

Info.

 
- Other lengths available on request

Accessories

- SHN nuts (tome 1 p.569)

- MCL and MHX sleeves

(tome 1 p.524-528)



DISCOUNTS

Qty	1+	5+	15+
Disc.	List -5%	On request	


Part number	ØF	L	Quantity per pack	Price each 1 to 4
TIF6-30/B	M6	30	200	26,73 €
TIF6-40/B	M6	40	200	32,16 €
TIF6-50/B	M6	50	200	36,56 €
TIF6-60/B	M6	60	200	47,48 €
TIF6-70/B	M6	70	200	51,88 €
TIF6-80/B	M6	80	200	55,20 €
TIF6-100/B	M6	100	200	68,31 €
TIF6-120/B	M6	120	200	79,26 €
TIF8-30/B	M8	30	200	36,56 €
TIF8-40/B	M8	40	200	44,25 €
TIF8-50/B	M8	50	200	49,68 €
TIF8-60/B	M8	60	200	60,63 €
TIF8-70/B	M8	70	200	66,15 €
TIF8-80/B	M8	80	200	72,70 €
TIF8-100/B	M8	100	200	83,67 €
TIF8-120/B	M8	120	200	149,94 €
TIF8-140/B	M8	140	200	140,56 €
TIF10-30/B	M10	30	100	29,21 €
TIF10-40/B	M10	40	100	31,95 €
TIF10-50/B	M10	50	100	35,24 €
TIF10-60/B	M10	60	100	41,83 €
TIF10-70/B	M10	70	100	51,08 €
TIF10-80/B	M10	80	100	58,81 €
TIF10-100/B	M10	100	100	66,96 €
TIF10-120/B	M10	120	100	88,85 €
TIF10-140/B	M10	140	100	100,89 €
TIF10-160/B	M10	160	100	115,12 €
TIF12-40/B	M12	40	100	40,71 €
TIF12-50/B	M12	50	100	48,37 €
TIF12-60/B	M12	60	100	57,65 €
TIF12-70/B	M12	70	100	68,07 €
TIF12-80/B	M12	80	100	80,13 €
TIF12-100/B	M12	100	100	94,34 €
TIF12-120/B	M12	120	100	127,16 €
TIF12-140/B	M12	140	100	146,30 €
TIF12-160/B	M12	160	100	167,66 €

Dimensions in mm

- Short threaded stud

- Material:

Stainless steel, 304

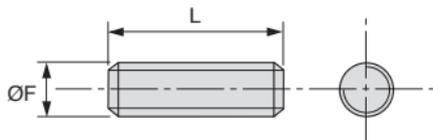

DISCOUNTS

Qty	1+	5+	15+
Disc.	List -5%	On request	

Part number	ØF	L	Quantity per pack	Price each 1 to 4
TIF6-30/SS/B	M6	30	100	56,82 €
TIF6-40/SS/B	M6	40	100	58,20 €
TIF6-50/SS/B	M6	50	100	63,15 €
TIF6-60/SS/B	M6	60	100	69,96 €
TIF6-70/SS/B	M6	70	100	77,23 €
TIF6-80/SS/B	M6	80	100	83,56 €
TIF6-100/SS/B	M6	100	100	97,16 €
TIF6-120/SS/B	M6	120	100	110,76 €
TIF8-30/SS/B	M8	30	100	59,54 €
TIF8-40/SS/B	M8	40	100	69,96 €
TIF8-50/SS/B	M8	50	100	80,85 €
TIF8-60/SS/B	M8	60	100	96,71 €
TIF8-70/SS/B	M8	70	100	112,10 €
TIF8-80/SS/B	M8	80	100	127,52 €
TIF8-100/SS/B	M8	100	100	140,20 €
TIF8-120/SS/B	M8	120	100	155,62 €
TIF8-140/SS/B	M8	140	100	177,81 €
TIF10-30/SS/B	M10	30	100	84,91 €
TIF10-40/SS/B	M10	40	100	102,60 €
TIF10-50/SS/B	M10	50	100	120,26 €
TIF10-60/SS/B	M10	60	100	136,58 €
TIF10-70/SS/B	M10	70	100	149,27 €
TIF10-80/SS/B	M10	80	100	164,67 €
TIF10-100/SS/B	M10	100	100	195,94 €
TIF10-120/SS/B	M10	120	100	227,67 €
TIF10-140/SS/B	M10	140	100	263,03 €
TIF10-160/SS/B	M10	160	100	299,29 €
TIF12-40/SS/B	M12	40	100	156,51 €
TIF12-50/SS/B	M12	50	100	190,04 €
TIF12-60/SS/B	M12	60	100	218,16 €
TIF12-80/SS/B	M12	80	100	276,61 €
TIF12-100/SS/B	M12	100	100	331,44 €
TIF12-120/SS/B	M12	120	100	389,02 €
TIF12-140/SS/B	M12	140	100	447,45 €
TIF12-160/SS/B	M12	160	100	518,60 €

Dimensions in mm