



TKUUOP Compensates for any flexing of the shaft

- Open self aligning linear bearing
- Integrated seals
- Material:
Housing: Thermoplastic
Balls: Steel 70 HRC ± 2




Accessories


- Z-A and Z-B hardened and ground shafts
- NSO and S20 housings

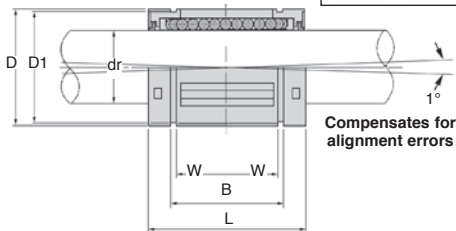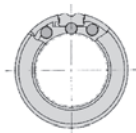


Compensates for alignment errors

 


TK-12

 

TK-16,20

 

TK-25

 

TK-30,40

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	dr	D	L	W	D1	h	J	G	B	θ	Loads		Stock*	Price each 1 to 4
											Dyn C(N)	Stat. Co(N)		
TK-12-UUOP	12	22	32	1,30	21,0	6,5	0,7	-	22,9	66°	1020	1290	✓	24,48 €
TK-16-UUOP	16	26	36	1,30	24,9	9,0	0,7	-	24,9	68°	1250	1550	✓	30,63 €
TK-20-UUOP	20	32	45	1,60	30,3	9,0	0,9	-	31,5	55°	2090	2630	✓	40,13 €
TK-25-UUOP	25	40	58	1,85	37,5	11,5	1,4	1,5	44,1	57°	3780	4720	✓	54,05 €
TK-30-UUOP	30	47	68	1,85	44,5	14,0	2,2	2,0	52,1	57°	5470	6810	✓	72,32 €
TK-40-UUOP	40	62	80	2,15	59,0	19,5	2,7	1,5	60,6	56°	6590	8230	✓	112,67 €

*Depending on availability - Dimensions in mm

Our other products



Free roller, Steel



 
Masterplate®
glueable insert Ø23,
Cylindrical Ø23 with
threaded s...



Spring hinge, welded



Hexagonal shaft,
Hexagonal shaft



RPP type belt per
metre, RPP14 Steel
cored polyurethane



Plastic clamping
collar, Ø10 - Ø20



Locking bolt support
bracket, Mounting
holes at 90° to
locating bolt



Retaining clamp,
single sided, Single
sided



Offset spur gear
reducer, from 111 to
425 Nm



Standard aluminium
profile, 19 x 45 mm

 


Pressed stainless
steel pillow block,
Stainless steel




Spring loaded toggle
latch, Standard
(GP75)

Complementary products



 Supported shaft for
linear guide, Steel
shaft / Aluminium
support



Supported shaft for
linear guide, Steel
shaft / Aluminium
support



Short housing for
open linear bearing,
Opened - slim