



TKUUOP Compensates for any flexing of the shaft

- Open self aligning linear bearing
- Integrated seals
- Material:
Housing: Thermoplastic
Balls: Steel 70 HRC ± 2




Accessories

- Z-A and Z-B hardened and ground shafts
- NSO and S20 housings

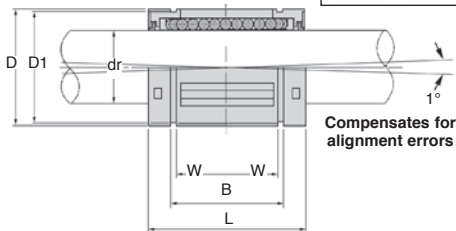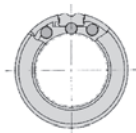

Compensates for alignment errors

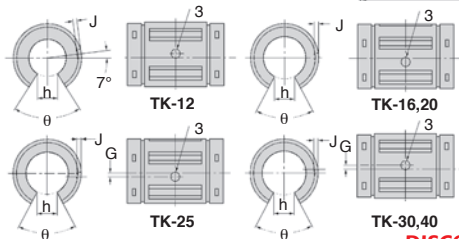

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	dr	D	L	W	D1	h	J	G	B	θ	Loads		Stock*	Price each 1 to 4
											Dyn C(N)	Stat. Co (N)		
TK-12-UUOP	12	22	32	1,30	21,0	6,5	0,7	-	22,9	66°	1020	1290	✓	24,48 €
TK-16-UUOP	16	26	36	1,30	24,9	9,0	0,7	-	24,9	68°	1250	1550	✓	30,63 €
TK-20-UUOP	20	32	45	1,60	30,3	9,0	0,9	-	31,5	55°	2090	2630	✓	40,13 €
TK-25-UUOP	25	40	58	1,85	37,5	11,5	1,4	1,5	44,1	57°	3780	4720	✓	54,05 €
TK-30-UUOP	30	47	68	1,85	44,5	14,0	2,2	2,0	52,1	57°	5470	6810	✓	72,32 €
TK-40-UUOP	40	62	80	2,15	59,0	19,5	2,7	1,5	60,6	56°	6590	8230	✓	112,67 €

*Depending on availability - Dimensions in mm

Our other products



PTA100ssEB
Articulated foot with sheet metal base Ø100, Articulated foot



PSG25S
Spur gear - precision range, Stainless steel 316



RCX-6
Spherical tilt washer - DIN6319, concave



GE14
Toggle latches, With padlock-holder



SLHVlok
Horizontal toggle clamp, Horizontal toggle clamp / vertical foot




PRF3232
Standard aluminium profile, 32 x 32 mm



VPSS
Small 6 lobe threaded handle - male, Duroplast - Stainless steel



 CHA_GC_9SS
Stainless steel garnet hinge, To be welded



RPP
Connecting plate for RPP type timing belts,



GAL48_OMNI
Omni-directional roller, Omni-directional roller




BAP25
Plastic clamping collar, Ø25 - Ø40




NPCR
Adjustable cell support, Adjustable

 Complementary products



 FTSN
Supported shaft for linear guide, Steel shaft / Aluminium support



FTSN
Supported shaft for linear guide, Steel shaft / Aluminium support



S20
Short housing for open linear bearing, Opened - slim