

 
 
 
 
 
 
 
 


## TKUUOP Compensates for any flexing of the shaft

- Open self aligning linear bearing
- Integrated seals
- Material:  
Housing: Thermoplastic  
Balls: Steel 70 HRC  $\pm 2$



### Accessories

- Z-A and Z-B hardened and ground shafts
- NSO and S20 housings

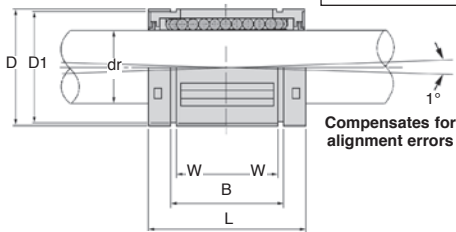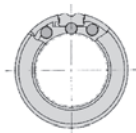

### DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	dr	D	L	W	D1	h	J	G	B	$\theta$	Loads		Stock*	Price each 1 to 4
											Dyn C(N)	Stat. Co(N)		
TK-12-UUOP	12	22	32	1,30	21,0	6,5	0,7	-	22,9	66°	1020	1290	✓	24,48 €
TK-16-UUOP	16	26	36	1,30	24,9	9,0	0,7	-	24,9	68°	1250	1550	✓	30,63 €
TK-20-UUOP	20	32	45	1,60	30,3	9,0	0,9	-	31,5	55°	2090	2630	✓	40,13 €
TK-25-UUOP	25	40	58	1,85	37,5	11,5	1,4	1,5	44,1	57°	3780	4720	✓	54,05 €
TK-30-UUOP	30	47	68	1,85	44,5	14,0	2,2	2,0	52,1	57°	5470	6810	✓	72,32 €
TK-40-UUOP	40	62	80	2,15	59,0	19,5	2,7	1,5	60,6	56°	6590	8230	✓	112,67 €

\*Depending on availability - Dimensions in mm

## Our other products



CHALss  
Piano hinge, Stainless steel



M1  
Worm and wheel set, Hardened steel



PRF\_FIX\_STD  
Fastener for aluminium profile, Standard fastener



HS  
Hexagonal spacer, Stainless steel 303



GE  
Toggle latches, Standard



CHM30  
Worm and wheel gear reducer, up to 28 Nm



PTA80  
Articulated levelling foot, pressed base Ø80, Ø 80



BOX-TOR-MAX  
Box set of Nitrile O-rings in nitrile, 2.90 x 1.78mm to 82.14 x 3.53



BSM\_LOK  
Long-Lok spring plunger with internal



GCA  
Lynch pin, Lynch



PCLA\_M  
Technopolymer clamping lever -

 


MPB  
Hexagonal spacer, Brass

## Complementary products



FTSN  
Supported shaft for linear guide, Steel shaft / Aluminium support



FTSN  
Supported shaft for linear guide, Steel shaft / Aluminium support



S20  
Short housing for open linear bearing, Opened - slim