



TKUU Compensates for any flexing of the shaft

- Self aligning closed linear bearing
- Compensates for any alignment errors or flexing of the shaft
- Integral seals
- Materials:
 Bearing: Thermoplastic
 Balls: Steel 70 HRC²



Accessories

- Z-A and Z-B hardened and ground shafts
- NSB and S2B housings

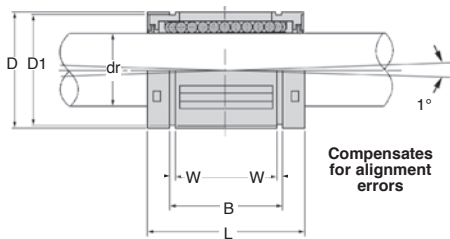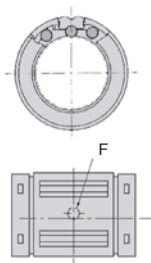

Until
-20%**

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	dr	D	L	W	D1	h	F	J	G	B	Loads		Price each 1 to 4	
											Dyn. C (N)	Stat. Co (N)		
TK-12-UU	12	22	32	1,30	21,00	-	3	0,7	-	22,9	1020	1290	✓ Stock*	21,44 €
TK-16-UU	16	26	36	1,30	24,90	-	3	0,7	-	24,9	1250	1550	✓	26,31 €
TK-20-UU	20	32	45	1,60	30,30	-	3	0,9	-	31,5	2090	2630	✓	34,10 €
TK-25-UU	25	40	58	1,85	37,50	-	3	1,4	1,5	44,1	3780	4720	✓	44,82 €
TK-30-UU	30	47	68	1,85	44,50	-	3	2,2	2,0	52,1	5470	6810	✓	61,39 €
TK-40-UU	40	62	80	2,15	59,00	-	3	2,7	1,5	60,6	6590	8230	✓	93,85 €

*Depending on availability - Dimensions in mm

Our other products



F7-SF-5M

Multifunction display,
Right angled
mounting bracket



GDR880

Straight track for slat
top chain, Ranges 880
and 881



WW20

Drylin® W slide, slide
assembly



SSG1

Stainless steel spur
gear, Stainless steel
304L



PAMF120

Articulated fixable
foot, pressed bolt-
down base Ø 120, Ø
120



KH

Linear bearing, Light



FBL6000_K13

Brush strip per meter
PP fibres Ø0.2, Black
striated polypropylene
...



F7-I

Multifunction display,
With internal sensor



VTFL

3 lobed handle,
Polyamide - Brass



PTMR

Telescopic furniture
foot, threaded stud



HTD5M_15

HTD Heavy duty
timing pulley, HTD5
Aluminium



LSAG

Sleeve for splined ball
shaft, Chariot - from
514 N to 15386 N

Complementary products



ZA

Shaft for linear
guides, Hardened
ground steel



ZB

Shaft for linear
guides, Hardened
ground stainless steel



ZA

Shaft for linear
guides, Hardened
ground steel